


**Modular/RJ Type Plug
4 Position 4 Contact**

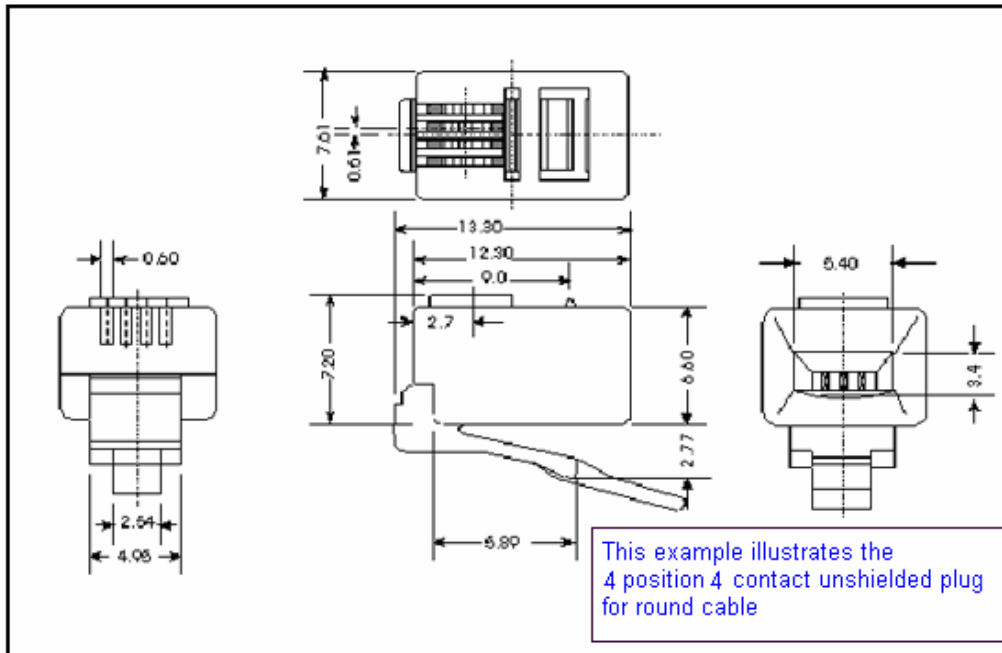

Features:

- Available for round and flat cable
- UL listed
- Contact blades are available for stranded or solid wire from 24-26 AWG
- Colour, special logos, fully-shielded or semi-shielded available to order

Specifications:

DIMENSIONS (as above, in mm)

MATERIALS

- Housing: Polycarbonate, UL94V
- Contacts: Gold plated over 100m Nickel plate over Phosphor Bronze