

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **2169454014**
Status: **Active**
Overview: Ultra-Fit Power Connectors
Description: Ultra-Fit Plug Housing, 3.50mm Pitch, Dual Row, 14 Circuits, Natural, Glow-Wire Capable

Documents:

[Drawing \(PDF\)](#) [Datasheet \(PDF\)](#)
[Product Specification 2169461000-PS-000 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Packaging Specification 2169451000-PK-000 \(PDF\)](#)

General

Product Family	Crimp Housings
Series	<u>216945</u>
Application	Power, Wire-to-Wire
Overview	<u>Ultra-Fit Power Connectors</u>
Product Name	Ultra-Fit
Taxonomy	Connector Housings
UPC	195842152939


Physical

Circuits (maximum)	14
Color - Resin	Natural
Gender	Plug
Glow-Wire Capable	Yes
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	Polyamide
Net Weight	4.000/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.50mm
Pitch - Termination Interface	3.50mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-40° to +105°C, -40° to +120°C

Material Info

Reference - Drawing Numbers

Packaging Specification	2169451000-PK-000
Product Specification	2169461000-PS-000
Sales Drawing	2169451000-SD-000

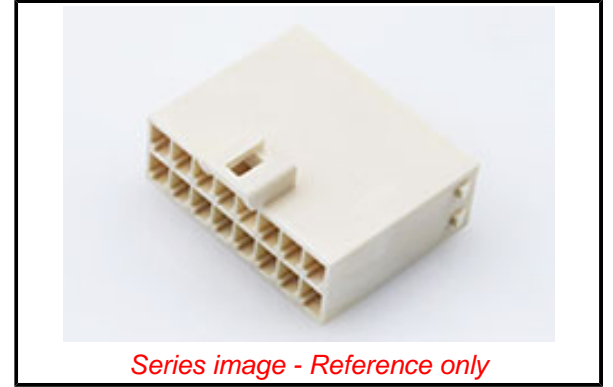

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

China RoHS

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

216945 Series

Mates With

Ultra-Fit Tangless Receptacle Housing
1722584114

Use With

Ultra-Fit Plug Terminal 216946 . Ultra-Fit Tangless TPA 1722643007

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION