


### C3C01UXXX

(M12 Cordset, 3 Position, 18 AWG, Female Straight to Free End)

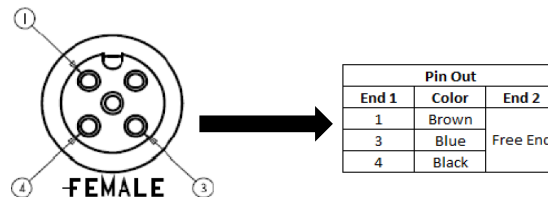

- Mueller's C3C01UXXX is an M12 3-pin single ended instrumentation cable with a straight female connector on one end and free at the other.
- Keyway – A Coding
- Utilizes our 3-conductor 18 AWG TPE-insulated cable.
- Ratings:
  - Current: 4 A
  - Voltage: 250 V AC/DC
  - Temperature Range: -40° C to 105° C
- Material:
  - Coupling Nuts – Aluminum
  - Pins/Contacts – Gold Plated Brass
- Length: The "U" in the model number represents unit of measurement.  
Either: Meters (M), Feet (F)
- Length: The "XXX" in the model number represents length. Standard lengths are 2, 5, and 10 meters. Any other lengths available upon request.
- Meets Standard: IEC 61076-2-101
- Protection Class: IEC IP68
- RoHS 3 Compliant