


## AI-T00216

(Receptacle, M12 Rear Mount, 8-Position Male Straight-Open, 1/2-14NPT Threads, 24 AWG, 0.3M)

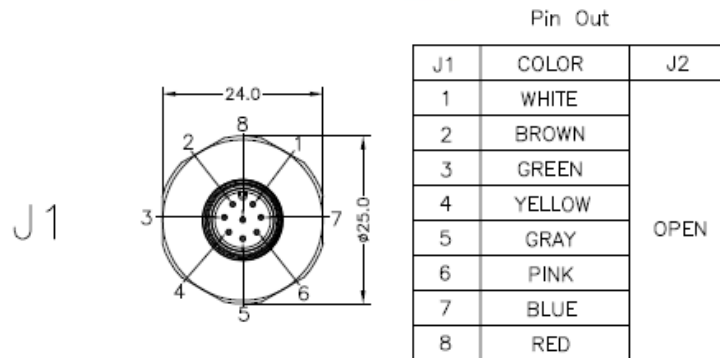

- Mueller’s AI-T00216 is a cable assembly that has a 8-position rear mount M12 Male receptacle to open end, 24 AWG, 0.3 meters.
- Shell size for connector: M12 (A Coding)
- Cable Material: 24AWG Hook Up Wire
  - Overall length = 0.984’ (0.3M)
- Shell: 24.2x25.4mm 1/2-14NPT threaded rear mount
  - Material: Nickel Plated Brass
- Rating:
  - Voltage: 60V AC/DC
  - Current: 4 Amps
  - Ambient Temperature: -40°C to 85°C
- Standard: IEC 61076-2-101
- Waterproof: IP67/IP68
- RoHS 3 Compliant