

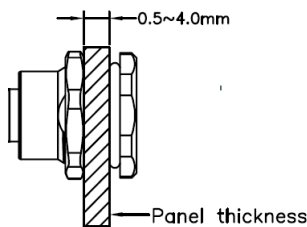


AI-T00204

(Receptacle, M12 Rear Mount, 4-Position Female Straight-Open, ¼-18NPT Threads, 22 AWG, 0.5M)

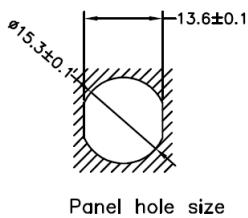

J1

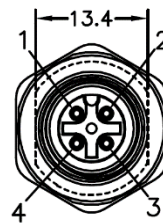

Pin Out

J1	COLOR	J2
1	BROWN	OPEN
2	WHITE	
3	BLUE	
4	BLACK	

- Mueller’s AI-T00204 is a cable assembly that has a 4-position rear mount M12 female receptacle to open end, 22 AWG, 2 meters.
- Shell size for connector: M12 (A Coding)
- Cable Material: UL 1569 22AWG Hook Up Wire
 - Overall length = 1.64’ (0.5M)
- Shell: 18x18mm ¼-18NPT threaded rear mount
 - Material: Nickel Plated Brass
- Rating:
 - Voltage: 250V AC/DC
 - Current: 4 Amps
 - Ambient Temperature: -40°C to 85°C
- Standard: IEC 61076-2-101
- Waterproof: IP67/IP68
- RoHS 3 Compliant