



NVENT CADDY CAT HP J-HOOK CLIP TO BC200 BEAM CLAMP, SWIVEL, 1/8"–5/8" FLANGE

CATALOG NUMBER

CATHPBC200B



CERTIFICATIONS



FEATURES

Easy installation to beam flanges

Rotates 360 degrees to support various directional runs of cable

Requires no screws, rivets or special tools for assembly

J-Hooks feature bendable locking tabs that lock on to nVent CADDY Cat HP components to provide rigidity and stability

Link to J-Hooks in one of multiple color options to aid in pathway identification and organization

Customized J-Hook trees can be easily assembled with various J-Hook sizes, colors and configurations

nVent CADDY Cat HP components easily attach to any size nVent CADDY Cat HP J-Hook


PRODUCT ATTRIBUTES

Material: Steel;Spring Steel

Finish: Electrogalvanized;nVent CADDY Armour

Flange Thickness: 1/8" – 5/8"

DIAGRAMS

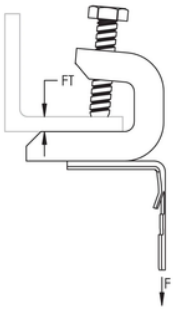

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER