



TE Internal #: 2063409-1
 Hand Crimping Tools, Commercial Crimp Tooling, Operator
 Releasable & Adjustable, Removable/Interchangeable, TE Product
 Specification (114-), Manual

[View on TE.com >](#)

Application Tooling > Hand Crimping Tools



Tool Grade: **Commercial Crimp Tooling**
 Ratchet Configuration: **Operator Releasable & Adjustable**
 Die Sets Type: **Removable/Interchangeable**
 Specification Type: **TE Product Specification (114-)**
 TE Certification: **No**

Features

Other

Crimp Form-Wire Barrel Type	Open Barrel - F Crimp
Tool Grade	Commercial Crimp Tooling
Ratchet Configuration	Operator Releasable & Adjustable
Die Sets Type	Removable/Interchangeable
Specification Type	TE Product Specification (114-)
TE Certification	No
Power Technology Type	Manual
Tooling Type	SDE Crimp Hand Tool

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Out of Scope
EU ELV Directive 2000/53/EC	Out of Scope
China RoHS 2 Directive MIIT Order No 32, 2016	Not reviewed for China RoHS compliance
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2023 (233) Candidate List Declared Against: JUL 2021 (219) Does not contain REACH SVHC
Halogen Content	Not Yet Reviewed for halogen content








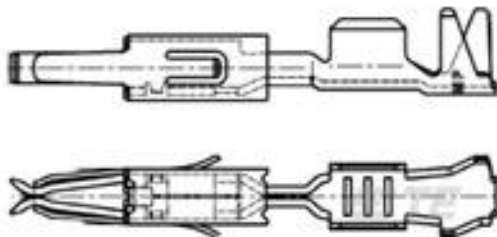




 

Solder Process Capability

Not applicable for solder process capability


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>



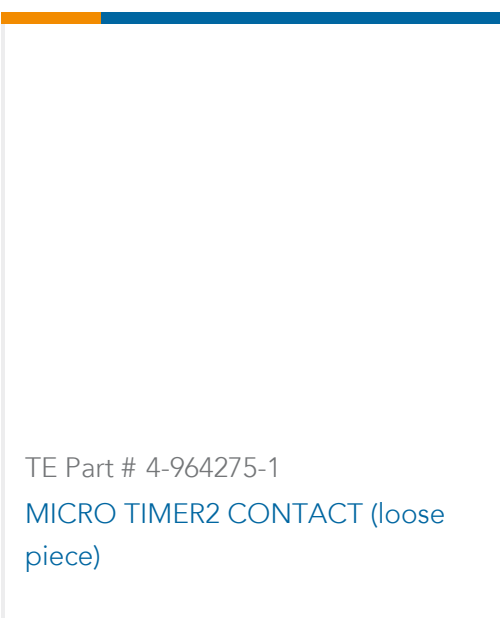

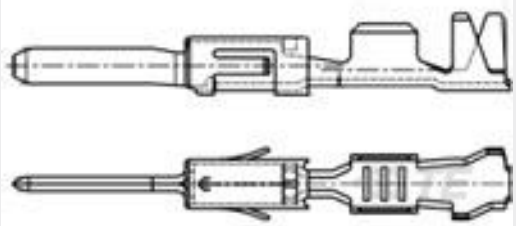


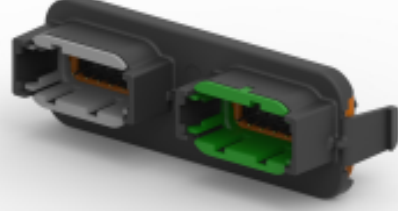
Compatible Parts

 <p>TE Part # 1-368067-2 MINI FUSE REC(JPT/PCB TYPE)</p>	 <p>TE Part # 1241327-1 MT2/SPT STE-VERB47P</p>	 <p>TE Part # 2063409-2 SDE MICROTIMER 0.2-1.0mm2 DIE SET</p>	 <p>TE Part # 964270-5 TAB A 1.6x0.6 CONTACT CS SWS Ag (LP)</p>
 <p>TE Part # 964270-2 TAB A 1.6x0.6 CONTACT CF SWS Sn (LP)</p>	 <p>TE Part # 964275-2 MT2 A REC 1.6 Contact SWS Sn (LP)</p>	 <p>TE Part # 1241731-2 MICRO TIM3 CONTACT</p>	 <p>TE Part # 2362810-1 SDE CRIMP HAND TOOL FRAME W /O DIES</p>
 <p>TE Part # 4-1241733-1 MICRO TIM2 CONTACT</p>	 <p>TE Part # 4-964262-1 MICRO TIM2 CONTACT</p>	 <p>TE Part # 4-964264-1 MICRO TIMER2 CONTACT LOOSE PIECE</p>	 <p>TE Part # 4-964275-1 MICRO TIMER2 CONTACT (Loose piece)</p>



<p>TE Part # 4-969019-1 MICRO TIMER2CONTACT</p>	<p>TE Part # 962944-3 MICRO TIM KONT</p>	<p>TE Part # 963899-1 MICRO TIM ST1,6X0,6</p>	<p>TE Part # 963899-2 MICRO TIM ST1,6X0,6</p>
<p>TE Part # 963899-3 MICRO-TIM ST1,6X0,6</p>	 <p>TE Part # 963901-3 TAB A 1.6x0.6 CONTACT CS SRC Au (LP)</p>	<p>TE Part # 963901-4 TAB A 1.6x0.6 CONTACT CS SRC Au (LP)</p>	<p>TE Part # 964266-3 TAB CONTACT 1,6X0,6 (LOOSE PIECE)</p>

Customers Also Bought

 <p>TE Part #HD14-9-1939PE INL REC ASM</p>	 <p>TE Part #2600046-2 18CCT RECEP BLACK KEYING B W /SEAL</p>	 <p>TE Part #HD34-24-91PN-072 REC, 9P, AL, N, THD ADPT DRAIN,8/12 /16,P</p>	 <p>TE Part #2371882-1 8POS,AMPSEAL,SOC HSG ASSY,SLD, COD 1</p>
 <p>TE Part #DT13-12PB-G003 HDR, 12P, BLK, RA, AU/NI/CU, B</p>	 <p>TE Part #YHDP24-24-35PEL024 REC, 35P, BLK, E, WTHD, 16/20, P</p>	 <p>TE Part #2338212-1 PLUG SOCKET ASSY, 4P, W2W, SEALED COAX</p>	 <p>TE Part #DTM1312PA12PCR008 HDR, 24P, BLK, RA EEC, NI/CU, AC</p>
<p>TE Part #HD10-6BT-BK BOOT, 6P, PLG/REC, ST, BLK</p>	<p>TE Part #HDB36-24-19PN-059 BR AWY PL ASM,MC</p>		

Documents



Datasheets & Catalog Pages

Bottoming Dies

English

Instruction Sheets

Instruction Sheet (U.S.)

English