

PC 2828 18 G-2FSH

FIBOX
Enclosing innovations



Sample image

Order symbol : PC 2828 18 G-2FSH

Product nr : 2539519

Description : Enclosure, PC



Remarks : Grey hinged cover

Including : Base with screws for mounting plate. cover with PUR gasket and polyamide cover screws.

EAN : 6418074052780

El. number :

- Finland : 3435740
- Sweden : 2539519

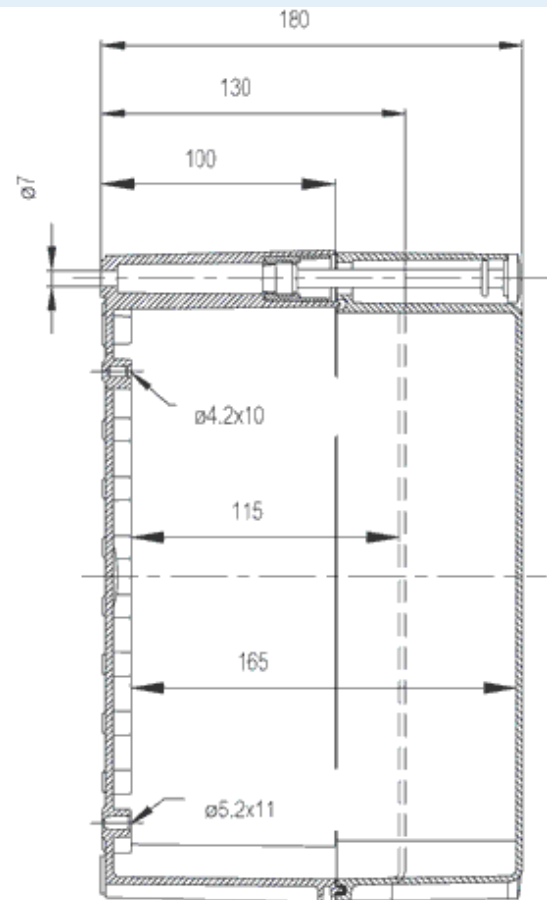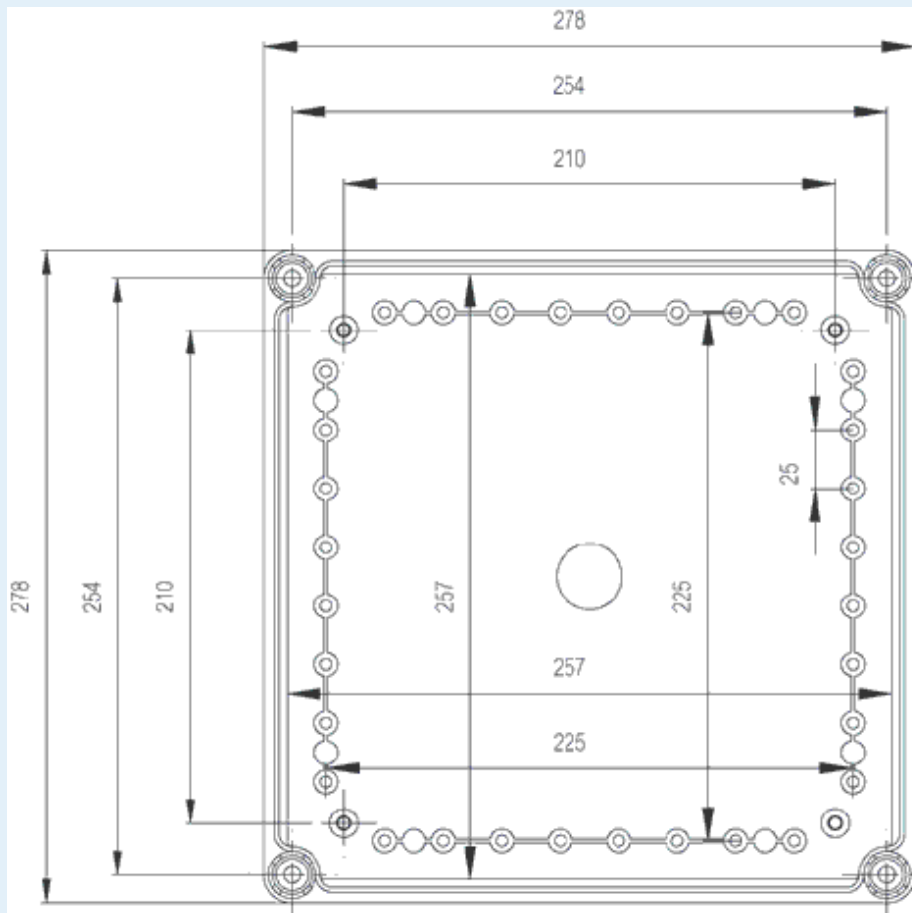

Dimensions :

	Height	Width	Depth
mm :	280	280	180

Accessories :

EKOZR

Extension frame, for enclosures:
(280 x 280 x 50)

inch : 11.02 11.02 7.09

Materials :

Material : Polycarbonate
Base colour : RAL 7035 -light grey
Cover colour : RAL 7035 -light grey
Gasket material : Polyurethane

Temperatures :

Temperature °C (short term) : -40 ... 120
Temperature °C (continuous) : -40 ... 80
Temperature °F (short term) : -40 ... 250
Temperature °F (continuous) : -40 ... 175

EKV 22 DIN-35 Mounting rail, for enclosures:
(235 x 35 x 1)
EKOVT Mounting plate, for enclosures:
(238 x 238 x 1)
MPI EKO 2828 Multiperforated plastic mounting plate
(244 x 244 x 4)

Ratings :

Ingress protection (EN 60529): IP65;
Impact Resistance (EN 62262): IK08;
Electrical insulation : Totally insulated
Halogen free (DIN/VDE 0472, Part 815) : Yes
UV resistance : UL 508
Flammability Rating : UL 746C 5"
Glow Wire Test (IEC 695-2-1) °C : 960 °C

Certificates :

Certificate NCS FI 30308