

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2196552121](#)
Status: **Active**
Overview: [Off-the-Shelf Pre-Crimped Leads](#)
Description: Pre-Crimped Lead Micro-One Female-to-Pigtail, Matte Tin Plating, 75.00mm Length, 22 AWG, Red

Documents:

[Drawing \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General

| | |
|------------------------|---|
| Product Family | Cable Assemblies |
| Series | 219655 |
| Application | Signal, Wire-to-Board |
| Assembly Configuration | Pre-crimped Lead Only |
| Connector to Connector | Micro-One-to-Pigtail |
| Overview | Off-the-Shelf Pre-Crimped Leads |
| Product Name | Micro-One |
| Taxonomy | Power and Signal Cable Assembl |
| UPC | 195842804074 |

Physical

| | |
|------------------------------|----------------------|
| Cable Length | 75.00mm |
| Circuits (Loaded) | 1 |
| Color - Resin | Red |
| Gender | Female-Pigtail |
| Material - Metal | Copper Alloy |
| Material - Plating Mating | Matte Tin |
| Net Weight | 0.503/g |
| Packaging Type | Bag |
| Plating min - Mating | 0.900µm |
| Plating min - Termination | 0.900µm |
| Single Ended | Yes |
| Termination Interface: Style | Crimp or Compression |
| Wire Insulation Diameter | 1.10-1.60mm |
| Wire Size AWG | 22 |
| Wire/Cable Type | UL 1569 |


Electrical

| | |
|-------------------------------|------------------|
| Current - Maximum per Contact | 4.0A |
| Voltage - Maximum | 250V AC (RMS)/DC |

Material Info

Reference - Drawing Numbers

| | |
|---------------|----------------|
| Sales Drawing | 2196551121-000 |
|---------------|----------------|

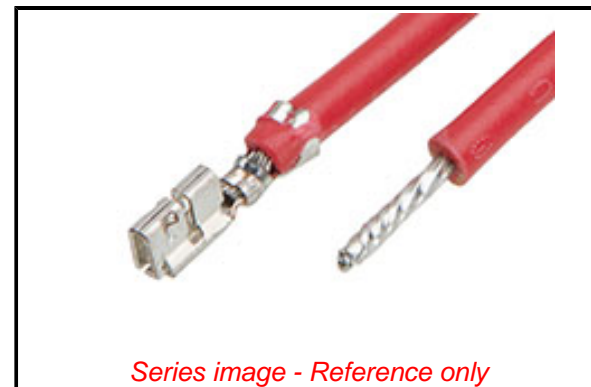

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained per -
D(2022)9120-DC (17
Jan 2023)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[219655](#) Series

Use With

Micro-One Receptacle Housing [205979](#) ,
[212724](#)