

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [2196791042](#)  
**Status:** **Active**  
**Overview:** Micro-Latch Wire-to-Board Connector System  
**Description:** Micro-Latch-to-Pigtail Off-the-Shelf (OTS) Cable Assembly, 2.00mm Pitch, Tin (Sn) Plating, 150.00mm Length, 4 Circuits, Natural

**Documents:**

[Drawing \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

**General**

|                        |   |
|------------------------|---|
| Product Family         | Cable Assemblies                                  |
| Series                 | <a href="#">219679</a>                            |
| Application            | Signal, Wire-to-Board                             |
| Assembly Configuration | Single Ended Connector                            |
| Connector to Connector | Micro-Latch-to-Pigtail                            |
| Overview               | <u>Micro-Latch Wire-to-Board Connector System</u> |
| Product Name           | Micro-Latch                                       |
| Taxonomy               | Power and Signal Cable Assembl                    |
| Type                   | Discrete Wire Assembly                            |
| UPC                    | 195842860063                                      |

**Physical**

|                                |                      |
|--------------------------------|----------------------|
| Cable Length                   | 150.00mm             |
| Circuits (Loaded)              | 4                    |
| Color - Resin                  | Natural              |
| Gender                         | Female-Pigtail       |
| Lock to Mating Part            | Yes                  |
| Material - Metal               | Phosphor Bronze      |
| Material - Plating Mating      | Tin                  |
| Material - Plating Termination | Tin                  |
| Material - Resin               | Polyester            |
| Net Weight                     | 2.864/g              |
| Number of Rows                 | 1                    |
| Packaging Type                 | Bag                  |
| Pitch - Mating Interface       | 2.00mm               |
| Plating min - Mating           | 0.900µm              |
| Plating min - Termination      | 0.900µm              |
| Single Ended                   | Yes                  |
| Termination Interface: Style   | Crimp or Compression |
| Wire Insulation Diameter       | 1.40mm               |
| Wire Size AWG                  | 22                   |
| Wire/Cable Type                | UL 10002             |


**Electrical**

|                               |                  |
|-------------------------------|------------------|
| Current - Maximum per Contact | 2.5A             |
| Voltage - Maximum             | 250V AC (RMS)/DC |

**Material Info**

**Reference - Drawing Numbers**

|               |                |
|---------------|----------------|
| Sales Drawing | 2196791040-000 |
|---------------|----------------|

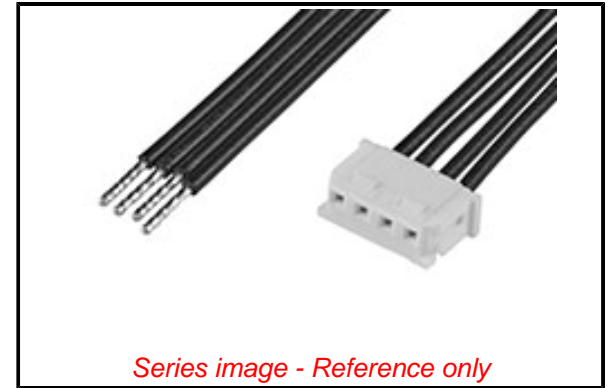

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained per -  
D(2022)9120-DC (17  
Jan 2023)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[219679 Series](#)

**Mates With**

Micro-Latch Vertical Header [53253](#) . Micro-Latch Right-Angle Header [53254](#)