

IDEAL[®] PLIERS

MADE IN THE USA

IDEAL Electrical is excited to introduce a new line of ergonomic Smart-Grip[®] handles. Designed for comfort and durability in all work environments, these next generation handles are built to perform. All IDEAL pliers now come with an integrated tethering hole, and letter indicator to easily identify the right tool for the job.



THE ELECTRICIAN'S
CHAMPION[™]




idealind.com

IDEAL[®] PLIERS

MADE IN THE USA


Heavy-Duty Dipped Grips

- Heavy-duty textured grips
- Excellent fit, form and functionality
- Dipped hot for uniform shape, optimum adhesion and perfect form

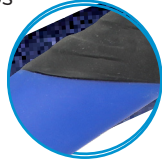

Smart-Grip™ Dual Durometer Molded Grips

- Designed for improved comfort
- Integrated tethering hole for added safety
- Letter indicator provides quick tool identification

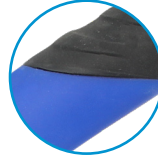

1000V Grips

- Permanently bonded double insulated handles for added safety
- Non-slip guard for added safety
- High visibility ergonomic handles for maximum comfort and control
- Textured handles provide a sure grip and are resistant to perspiration, water, oil and chemicals



Linesman Pliers

- Knife-to-knife blades provide excellent cutting performance
- Cuts hardened wire, bolts and stainless steel wire
- Fine grain cross-hatched nose grabs wire without damage to fine strands



Diagonal-Cutting Pliers

- Knife-to-knife blades provide excellent cutting performance
- High-leverage design provides more cutting power
- Angled head for hard-to-reach areas and rocking out nails



Description	Part Numbers		
	Dipped Grip	Smart-Grip™	Insulated
9-1/2 in. Linesman Pliers w/ New England nose, crimping die and fish tape puller	30-430	30-3430	30-9430
9-1/2 in. Linesman Pliers	30-450	30-3450	—

Description	Part Numbers		
	Dipped Grip	Smart-Grip™	Insulated
8 in. Diagonal-Cutting Pliers	35-028	35-3028	—
8 in. Diagonal-Cutting Pliers w/angled head	35-029	35-3029	35-9029

Long-Nose Pliers

- Narrow profile head designed for working in tight areas
- Serrated jaws provide secure gripping surface
- Laser-hardened blades cut hardened wire, bolts and stainless steel wire



Tongue & Groove Pliers

- Reinforced flange protects against breakage
- Drop-forged, high-carbon steel construction



Description	Part Numbers		
	Dipped Grip	Smart-Grip™	Insulated
6 in. Long-Nose Pliers w/cutter	35-036	—	—
8-1/2 in. Long-Nose Pliers w/cutter	35-038	35-3038	35-9038

Description	Part Numbers		
	Dipped Grip	Smart-Grip™	Insulated
9-1/2 in. Tongue & Groove Pliers	35-420	35-3420	35-9420
7 in. Tongue & Groove Pliers	35-426	—	—
12 in. Tongue & Groove Pliers	35-440	—	—



IDEAL INDUSTRIES, INC.

IDEAL INDUSTRIES, INC.

1800 S. Prairie Drive, Sycamore, IL 60178, USA / 815-895-5181 • 800-435-0705 in USA

International offices:

Australia • Canada • China • India • Mexico • UK

For complete sales office contact information, visit us at:

www.idealind.com