

## Product information

# 12 52 195

## KNIPEX PreciStrip16 Automatic Insulation Stripper



- Simple, precise stripping of fine wires and solid round cables with a wide capacity range from 0.08 to 16 mm<sup>2</sup> with only one pair of pliers
- Good grip provided by semi-circular grooved metal holding clamps; exact cut thanks to parabolic stripping blade
- A patented automatism regulates the depth of the cut; the neutral point of the automatism can be adjusted in fine steps in special operating conditions (insulation material, temperature)
- With adjustable length stop for precision work repeated accurately each time
- Inscription area for customisation
- Comfortable operation with ergonomic dual-component handle
- With tether attachment point, suitable for KNIPEX Tethered Tools accessories
- Easily replaceable blade cassette





### General




Article No.	12 52 195
EAN	4003773085829
Weight	180 g
Dimensions	190 x 120 x 28 mm
REACH compliant	contains SVHC
RoHS compliant	not applicable



### Technical details

Stripping capacities in square millimetres	0.08 — 16.0 mm <sup>2</sup>
AWG	28 — 6

*technical change and errors excepted*

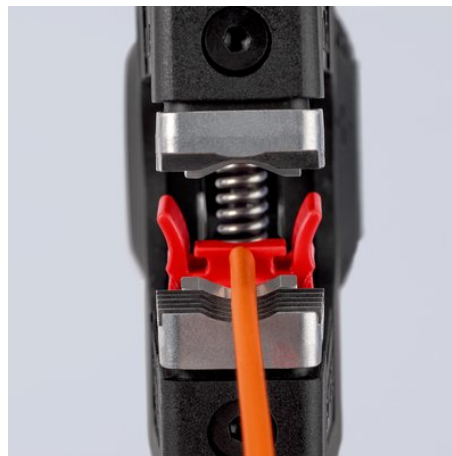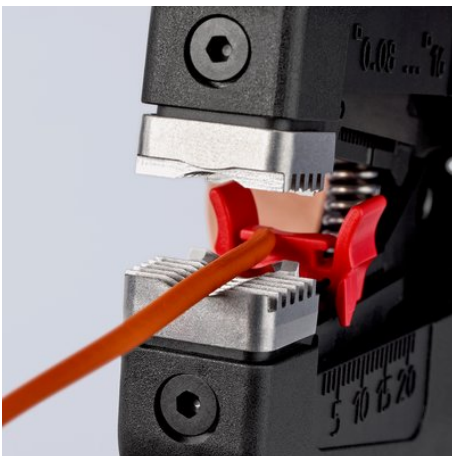

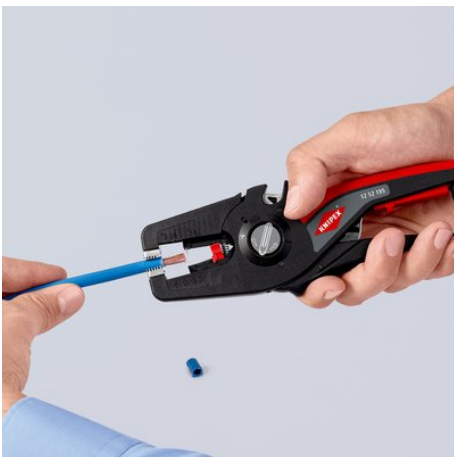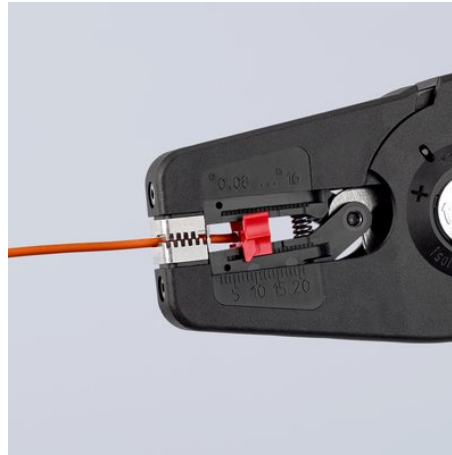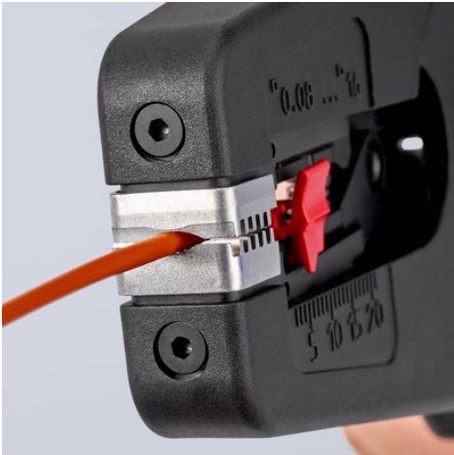

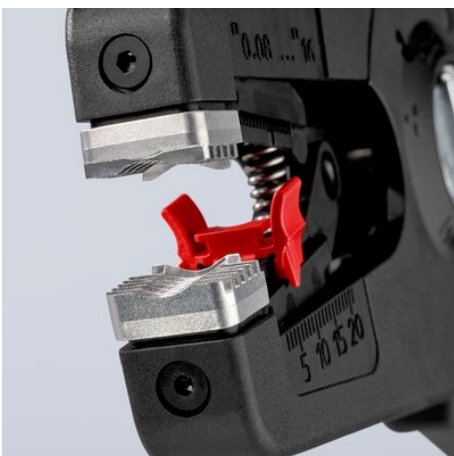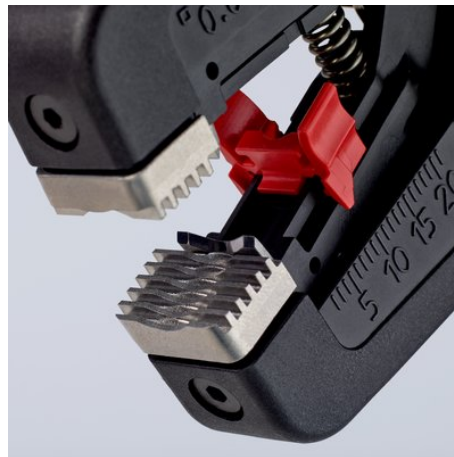

Semi-circular grooved holding clamp for better grip that holds practically any insulation material securely in place

For special requirements, such as particularly hard or soft insulation materials, optimum fine adjustments can be made using the adjusting wheel with its tactile locking positions



With cable cutter on the top side for up to 16 mm<sup>2</sup>