




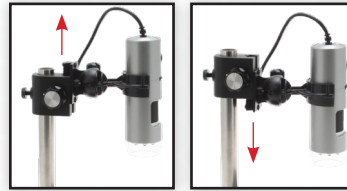


Plug & Play	High Magnification	Adjustable Illumination	Diffuser Attachment
Connect to PC via USB	Up to 200x~ <small>(based on a 24" monitor)</small>	Built-in 8 white-light LEDs	Reduces glare & provides even illumination

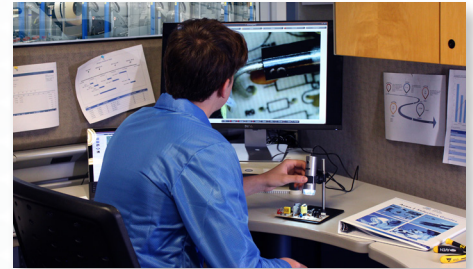


Adjustable Focus Mount

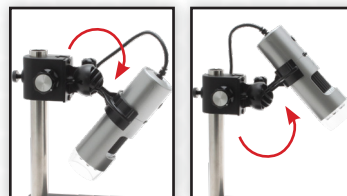

Great for a Wide Range of Applications

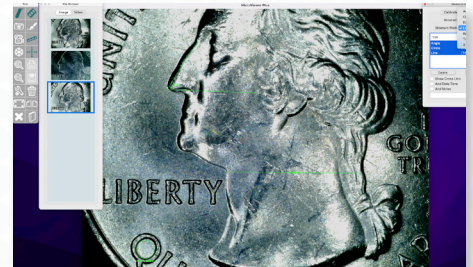

MicroViewer Plus Software
Connect to PC via USB

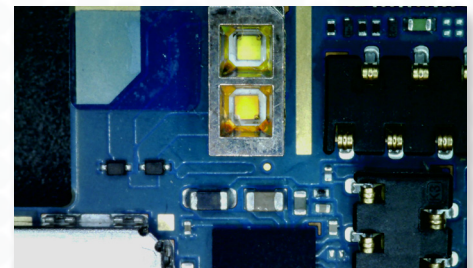

**High Magnification
Exceptional Clarity**


Mighty Scope v2

USB Digital Microscope with Diffuser


Convenient and sophisticated, Aven's Mighty Scope v2 USB Digital Microscope with diffuser features a plug-and-play USB interface for an easy computer link, as well as adjustable magnification, image and video capture, a large working distance and a broad magnification range of up to 200x~ (based on a 24" monitor).

Key Features

- 10x - 200x~ Magnification (based on a 24" monitor)
- Enhanced Image Sensor (1/4" Color CMOS)
- The diffuser provides soft & even illumination for shiny and reflective parts
- Improved depth of field
- Adjustable 8 energy-efficient LED lights
- Includes fine-focus metal stand
- MicroViewer Plus Software optimized for the Mighty Scope v2 w/ all of the measurement and image/video capabilities needed for professional inspection

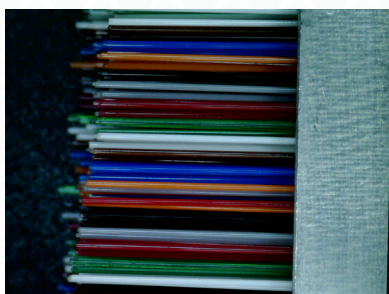

With Diffuser

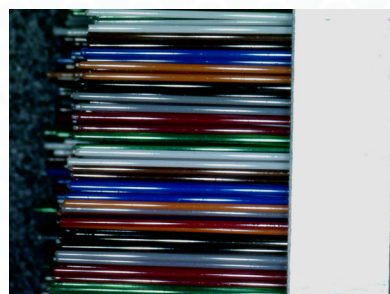

Without Diffuser

Mighty Scope v2				
<i>USB Digital Microscope with Diffuser</i>				
Item #	26700-218-DFS			
Magnification	10x - 200x~ (based on a 24" monitor)			
Working Distance	10x	20x	30x	40x
	112mm	42mm	19mm	8.5mm
Resolution	5MP, 2592 (H) x 1933 (V)			
Illumination	8 White-light adjustable LEDs			
Output	USB			
PC Software	MicroViewer Plus			
Package Contents	<ul style="list-style-type: none"> • Mighty Scope v2 • MicroViewer Plus (Downloadable PC Software) • Diffuser Attachment for Mighty Scope v2 • User Manual • Fine Focus Stand • Microscope Mount 			