




### Magnetic Buzzer

## EMX-300P<sub>2</sub>SIRIES



**DIMENSIONS:(Unit: mm)**

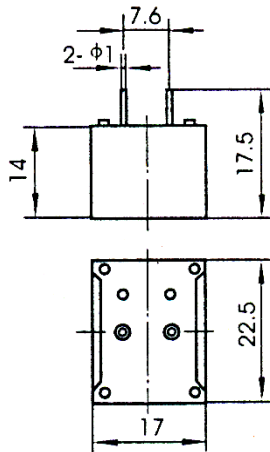

**FEATURES:**


- Low Current
- Compact
- Rich Sound

**APPLICATIONS:**

- Automatic Control Equipment
- Communication Equipment
- Electronic Instruments

**CHARACTERISTICS:**

*EMX-312P<sub>2</sub>*

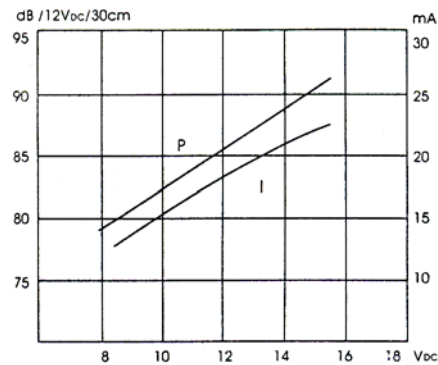

**ELECTRICAL SPECIFICATIONS :**

Model No.	EMX-301P <sub>2</sub>	EMX-303P <sub>2</sub>	EMX-306P <sub>2</sub>	EMX-309P <sub>2</sub>	EMX-312P <sub>2</sub>	EMX-324P <sub>2</sub>
Min. Sound Pressure Level /Rated Voltage/30cm (dB)	70		75			
Rated Voltage (V <sub>DC</sub> )	1.5	3	6	9	12	24
Operating Voltage (V <sub>DC</sub> )	1~ 3	2~ 4	4~ 8	9~ 12	9~ 15	15~ 27
Rated Current (mA)	20	25				30
Resonant Frequency (Hz)	400±50					
Operating Temperature (°C)	-20~ +70					
Weight (g)	8					

**PACKING INFORMATION:**

Packing: 1500 pcs per export cartone

Carton Size: 47×30.5×35 cm

G. Weight: 14 kgs N. Weight: 12 kgs

Address: No. 12. Lane 722. Sangtian Road Jiangdong Science Garden Ningbo 315040. P. R. China

Fax No: (0574)87803761

Tel: (0574) 87802511

