


PX2000P03BK Datasheet

Product Name // 3 Contacts Male Automotive Rectangular Black Connector

[View Product Page](#)

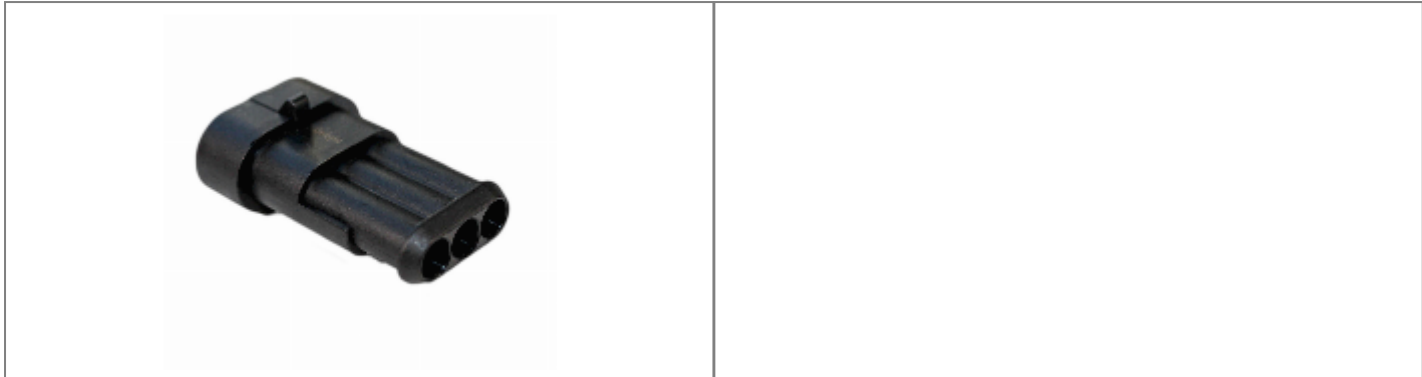

// Product Description:

- ⊞ 3 Contacts Male Automotive Rectangular Black Connector
- ⊞ IP67 rated when mated
- ⊞ Mate with PX2001 Series
- ⊞ Wedge locks provided
- ⊞ Crimp Terminals
- ⊞ Mechanical Cycles=100 (min)
- ⊞ Operating Temperature= -40Â°C to +125Â°C

// General Information:

Product Display Title:	3 Contacts Male Automotive Rectangular Black Connector
Product Family:	Rectangular Connectors
Product Series:	Automotive Rectangular Connectors
Body Colour:	Black
Body Material:	Polybutylene Terephthalate (PBT)
Body Material Type:	Plastic Body
Contact Type:	Socket Contact
Coupling Type:	Snap-in
Current Max:	14A
Dielectric Withstanding Voltage:	1500V
Durability:	>100 Cycles
Function:	Straight Male Connector
Insulation Resistance:	>2000MOhms
Ip Rating:	IP67
Max Operating Temperature:	+125°C
Min Operating Temperature:	-55°C
Number Of Contacts:	3 Contacts
Rohs Compliant:	Yes
Voltage Max:	24V

// Product PDF Links

[Rectangular Power Connector...](#)