


PX0011P04GY Datasheet

Product Name // 4 Contacts Female Miniature Rectangular Grey Connector

[View Product Page](#)

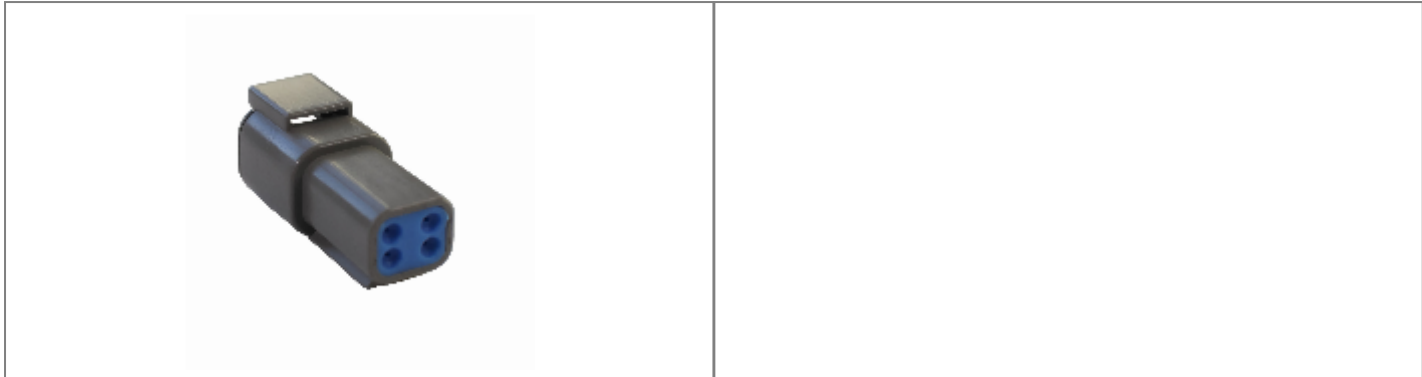

// Product Description:

- ⊗ 4 Contacts Female Miniature Rectangular Grey Connector
- ⊗ Protective End Cap (PEC) Available
- ⊗ IP68 rated when mated
- ⊗ Mate with PX0010 Series
- ⊗ Wedge locks provided
- ⊗ Crimp Terminals
- ⊗ Mechanical Cycles=100 (min)
- ⊗ Operating Temperature= -55Â°C to +125Â°C

// General Information:

Product Display Title:	4 Contacts Female Miniature Rectangular Grey Connector
Product Family:	Rectangular Connectors
Product Series:	Miniature Rectangular Connectors
Body Colour:	Grey
Body Material:	Polycarbonate/Polybutylene Terephthalate (PC/PBT)
Body Material Type:	Plastic Body
Contact Type:	Plug Contact
Coupling Type:	Snap-in
Current Max:	7.5A
Dielectric Withstanding Voltage:	1500V
Durability:	>100 Cycles
Function:	Straight Female Connector
Insulation Resistance:	>1000MOhms
Ip Rating:	IP68
Max Operating Temperature:	+125°C
Min Operating Temperature:	-55°C
Number Of Contacts:	4 Contacts
Rohs Compliant:	Yes
Voltage Max:	250V

// Product PDF Links

[Rectangular Power Connector...](#)