


# PX0010S04GY Datasheet

## Product Name // 4 Contacts Male Miniature Rectangular Grey Connector

[View Product Page](#)

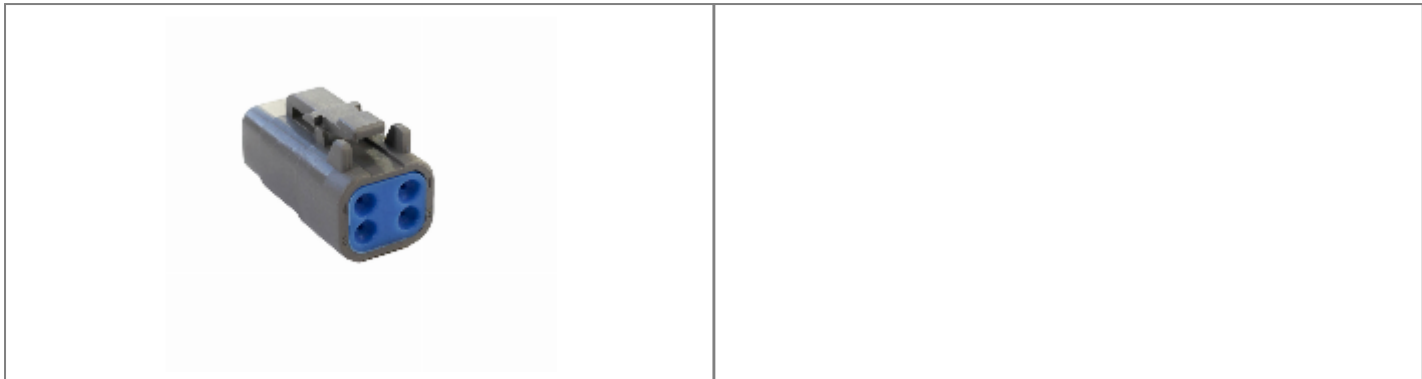

### // Product Description:

- ⊕ 4 Contacts Male Miniature Rectangular Grey Connector
- ⊕ Protective End Cap (PEC) Available
- ⊕ IP68 rated when mated
- ⊕ Mate with PX0011 Series
- ⊕ Wedge locks provided
- ⊕ Crimp Terminals
- ⊕ Mechanical Cycles=100 (min)
- ⊕ Operating Temperature= -55Â°C to +125Â°C

### // General Information:

Product Display Title:	4 Contacts Male Miniature Rectangular Grey Connector
Product Family:	Rectangular Connectors
Product Series:	Miniature Rectangular Connectors
Body Colour:	Grey
Body Material:	Polycarbonate/Polybutylene Terephthalate (PC/PBT)
Body Material Type:	Plastic Body
Contact Type:	Socket Contact
Coupling Type:	Snap-in
Current Max:	7.5A
Dielectric Withstanding Voltage:	1500V
Durability:	>100 Cycles
Function:	Straight Male Connector
Insulation Resistance:	>1000MOhms
Ip Rating:	IP68
Max Operating Temperature:	+125°C
Min Operating Temperature:	-55°C
Number Of Contacts:	4 Contacts
Rohs Compliant:	Yes
Voltage Max:	250V

// Product PDF Links

[Rectangular Power Connector...](#)