

RF Product Information

- RFFPA851008IMUB301 Series for UHF Application at 433 MHz

Application

- UHF 433 MHz in Smart Meter, Industrial Data Acquisition System and Door Control System
- Device for external UHF system

Recommended Link Parts

RFCON030300IF6B002(On Board RF Connector)




ELECTRICAL CHARACTERISTICS

Item	Specification
Frequency Range	433 MHz
Impedance	50 Ohm Nominal
VSWR	2 Max.
Radiation	Omni-directional
Polarization	Linear Vertical
Admotted Power	1W

MATERIAL TABLE

Item	Description
Antenna	FPC(Black)
Connector	IPEX Compatible(Gold)
Double Tape	3M9888T
Cable	φ 1.13 Cable;Gray

ELECTRICAL
Frequency :
433 MHz

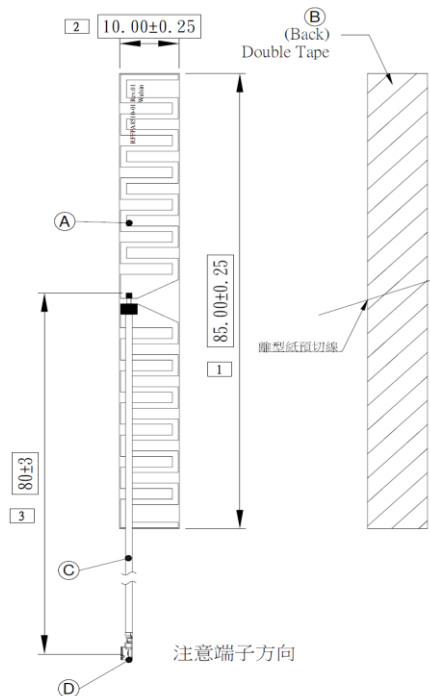

INFORMATION

For more information, please contact with
[Walsin Technology Corporation](http://www.walsin.com)
 Tel : 886-3-475-8711
 Fax : 886-3-475-5197
 E mail : info@passivecomponent.com
 Web Site : http://www.passivecomponent.com