


SEARCH KEYWORD, PART NUMBER



Part Number: 10736278

SINGLE WIRE SEAL FITS TO 4.4 mm CAVITY

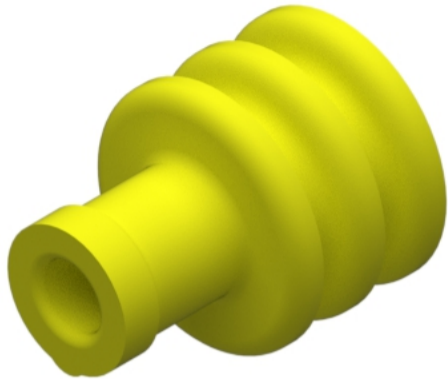

Attributes

Type	Color
SINGLE WIRE SEAL	YELLOW
Outer Diameter (mm)	Hardness (Shore)
5	54
Borehole Diameter (mm)	Contains Lubricant (Oil Content)
0.9	Low
Length (mm)	Min. operating temperature
6.65	-40°C
Min Cable Outer Diameter (mm)	Max. operating temperature
1.25	+140°C
Max Cable Outer Diameter (mm)	
1.9	