

# L 24 II



Sample image

**Order symbol :** L 24 II

**Product nr :** 3730776



**Description :** Window for 24 modules

**Remarks :** Smoked transparent cover

**EAN :** 6418074036858

**El. number :**

- Finland 3422654
- Denmark 8212051234
- Sweden 2539789

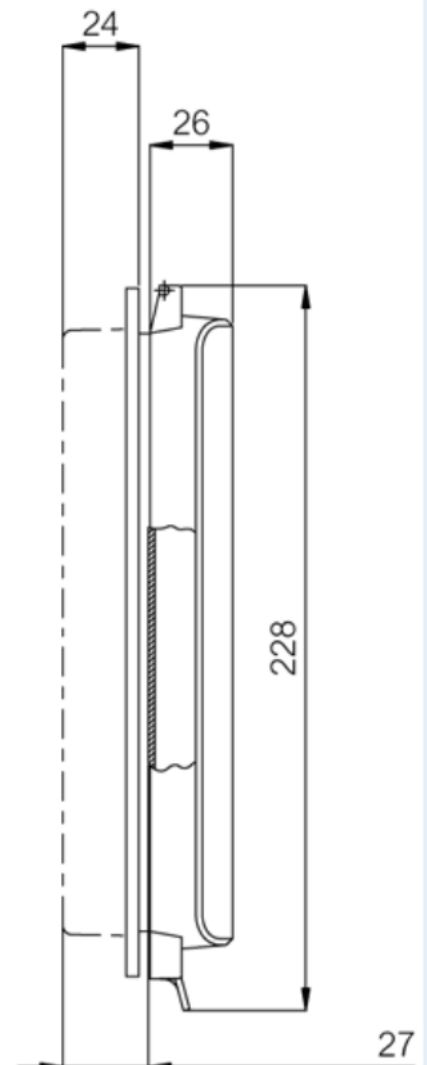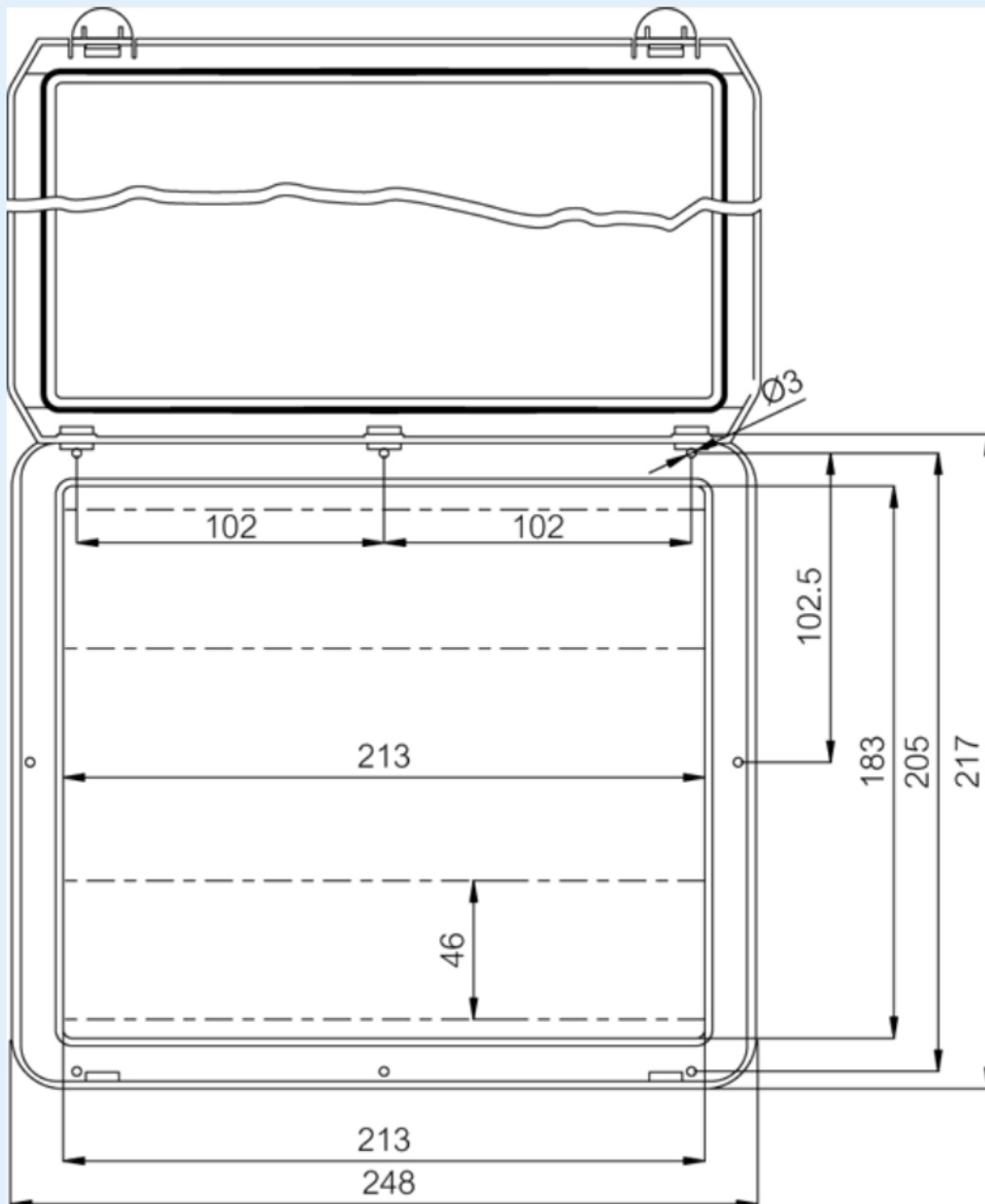

**Dimensions :**

	Height	Width	Depth
mm :	248	218	0
inch :	9.76	8.58	0

**Temperatures :**

Temperature °C (short term) :	-40 ... 120 °C
Temperature °C (continuous) :	-40 ... 80
Temperature °F (short term) :	-40 ... 250
Temperature °F (continuous) :	-40 ... 175

**Ratings :**

Ingress protection (EN 60529):	IP65;
Impact Resistance (EN 62262):	IK08;
Electrical insulation :	Not insulated
Halogen free (DIN/VDE 0472, Part 815) :	No
UV resistance :	-