

Product Datasheet

Product code: **10G.SA.0**

Product type: High precision tweezers

Made in: Switzerland


Description: Type 10G high precision tweezers are suitable to delicate applications which require holding a component very firmly while granting good visibility. The line serration provides the tips and the handles with extra grip, also preventing any possible slips.

Tip description: straight, thick, beveled, line serrated, superior finish

Coating/finishing: Sandblasted


Body material: Anti-Magnetic Anti-Acid Stainless Steel (SA)

Picture:

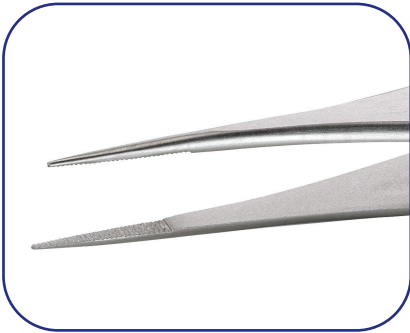

Tweezer dimensions:

OAL	110.0 mm – 4.331 inch
Width	10.0 mm – 0.394 inch
Height	12.0 mm – 0.472 inch

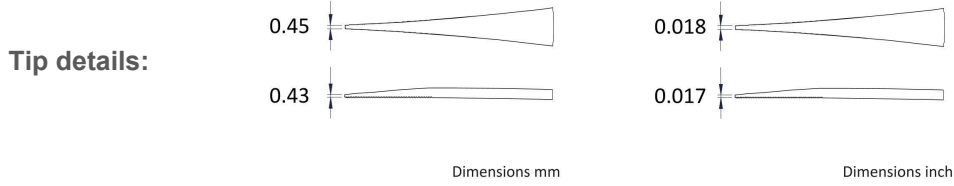

Tip dimensions:

Tip width	0.45 mm – 0.018 inch
Tip thickness	0.43 mm – 0.017 inch