


# Part Number: R-3W-DC

<span>DC Voltage Indicator with Flashing LEDs</span>

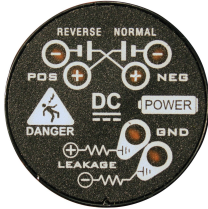

<https://shop.graceport.com/products/r-3w-dc>






## Product Specifications

Component Details	
Part Number	R-3W-DC
Electrical Specifications	
Voltage Indicator	Flashing LEDs
Voltage Type	DC
Operational Voltage Range	20-600VAC, 50/60/400Hz, 15-1000VDC
Storage Temperature Range	-45°C to + 55°C
Operational Temperature Range	-40°C to +55°C
Voltage to Door Required	Yes
Lead Connections	1 Phase, 3 Wire
Mechanical Specifications	
Installation	30mm Pushbutton Hole
Mounting Location	External (Door/Flange Mounted)
Commercial Data	
Country of Origin	Taiwan
Schedule B Code	8531.80.9051

### Approval Certifications

Logo	Approval	Additional Text	Certificate Name	
	UL Underwriters Laboratories Inc.		E256847	

### Datasheets

Name	
Voltage Indicator Datasheet	
Voltage Indicator Datasheet Spanish	
DC Voltage Indicator Installation Guide	

### Don't see what you're looking for?

Contact us at [sales@gracetechnologies.com](mailto:sales@gracetechnologies.com), call 1-800-280-9517 or visit [www.graceport.com](http://www.graceport.com) to chat with our customer service.