

- > tightly holds round or flat material
- > heavy-duty
- > adjustment screw and release lever for easy use
- > one-handed operation
- > high damping pressure due to toggle lever action
- > pliers body: rolled steel, high-strength
- > gripping jaws: chrome vanadium electric steel; forged

Style 0

Jaws for round workpieces, with wire cutter

Style 1

Jaws with double prism for round, section and flat material

Style 2

Straight jaws for flat material

Style 3

Long Nose Grip Pliers, narrow, long jaws

Style 4

Long Nose Grip Pliers, narrow long jaws very suitable for areas that are difficult to reach. Non-serrated gripping area for pinching off hoses




41 04 250



41 14 250




41 24 225

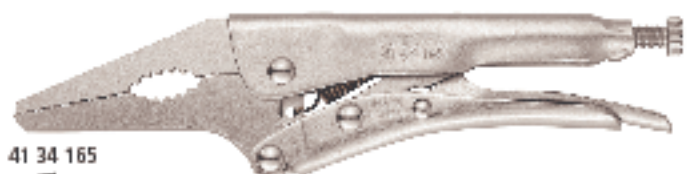

41 34 165



 41 44 200



WARNING: This product can expose you to chemicals including Diisobutyl Phthalate, which is known to the State of California to cause cancer. For more information go to www.P65Warnings.gov

Product Number	Packaging	↔ Inch mm		Pliers	Style	□ Inch mm	⬡ Inch mm	⚖ lbs
41 04 180		7 1/4 180			0	1 3/16 30	1 3/16 30	0.82
41 04 250		10 250	🔧	bright zinc plated	0	1 37/64 40	1 3/16 30	1.23
41 04 300		12 300			0	2 9/16 65	1 11/32 34	2.08
41 14 250		10 250	🔧	bright zinc plated	1	1 27/64 36	1 27/64 36	1.29
41 24 225		9 225	🔧	bright zinc plated	2	1 25	1 3/16 30	1.16
41 34 165		6 1/2 165	🔧	bright zinc plated	3	13/16 20	15/16 24	0.42
41 44 200		8 200	🔧 70°	bright zinc plated	4	13/16 20	1 3/16 30	0.88