



/ Home / Products / Crimping Pliers / Four-Mandrel Crimping Pliers for turned contacts


97 52 65 DG A

Four-Mandrel Crimping Pliers for turned contacts

MM * 45°

- Crimping capacity can be adjusted in increments of 0.01 mm
- With digital display of the preset crimping capacity and possibility of re-calibration via RESET function with electronic wear monitoring
- Adjustment in mm, inches or comparable selection positions according to MIL
- With table for calculating the settings
- Pliers in a plastic case with foam insert
- Without locator



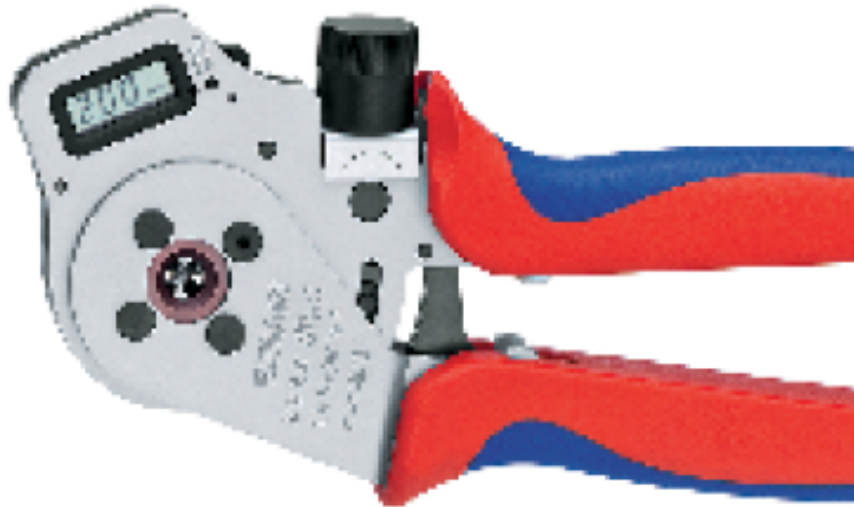

- For crimping turned contacts
- Four-mandrel crimping for top-quality crimping connections
- Mandrel gauge to check the basic setting
- Repetitive, high crimping quality due to ratchet mechanism (unlockable)
- Optimum transmission of force due to highly effective lever action for fatigue-reduced operation
- High operation comfort thanks to handy shape

Length

250 mm ▼





1/4

Technical attributes

Article No.	97 52 65 DG A
EAN	4003773071990
Pliers	chrome-plated
Head	chrome-plated
Handles	with multi-component grips
Weight	633 g
Dimensions	250 x 86 x 19 mm
REACH compliant	contains SVHC
RoHS compliant	not applicable
Application	turned contacts (Harting; Ilme; Phoenix; Amphenol; Walther; HTS; Contact; Weidmüller)



Capacity in square millimetres 0.14 – 6 mm²

AWG 26 – 10

Number of crimping positions 1

Max. contact diameter 7.5 mm

For calibration inquiries, please contact our affiliated company RENNSTEIG WERKZEUGE GMBH under the following contact:

Mr. Uwe Wagner

u.wagner@rennsteig.com

Tel .: +49 36 847 441-59

Domestic sales



www.rennsteig.com



Suitable accesories



97 59 65 2

Universal Locator for 97 52



65 / 97 52 65 A / 97 52 65 DG

/ 97 52 65 DG A

1/1

All variations



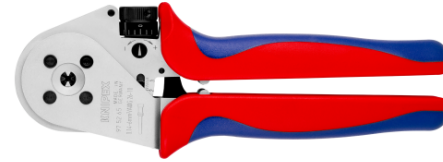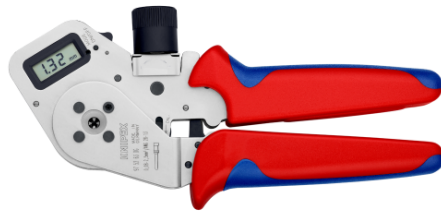

97 52 63

Four-Mandrel Crimping Pliers
for turned contacts

141-180 mm

0,08 – 2,5 mm²

Length: 180 mm

97 52 63 DG

Four-Mandrel Crimping Pliers
for turned contacts

0,08 – 2,5 mm²

Length: 195 mm

97 52 65

Four-Mandrel Crimping Pliers
for turned contacts

0,14 – 6,0 mm²

Length: 230 mm

97 52 65 A

Four-Mandrel Crimping Pliers
for turned contacts

0,14 – 6,0 mm²

Length: 250 mm

97 52

Four-M
for tur

0,14 –

Length

1/6

Technical changes and errors reserved.



Facebook





Instagram



Youtube



® LinkedIn

[Newsletter](#)

[Career](#)

[Contact](#)

[Terms and Conditions](#)

[Copyright](#)

[Imprint](#)

[Data protection](#)

[Privacy settings](#)

