

# MASTER Value GLASS LED candles and lustres

## MASTERVLE LEDCandleDT3.4-40WE14 927B35CLGUK

MASTER Value Glass LED lustres feature a classic heritage design, these filament LED lamps combine the familiar shapes of incandescent candles and lustres with the benefits of long-lasting LED technology. These glass LED lustres offer more energy savings than normal LED candles and lustres. At the same time, they also provide customers with a good light experience, enhanced by excellent dimming performance (dimmable LED candles). MASTER Value Glass LED lustres deliver significant energy savings, using 30% less energy compared to normal glass LED candles and provide excellent quality of light. By offering a lifetime of 15,000 hours, these dimmable LED candles and lustres also reduce maintenance costs.

### Product data

General information	
Cap base	E14 [E14]
EU RoHS compliant	Yes
Nominal lifetime	15,000 h
Switching cycle	20,000
Lighting Technology	LED
Brand	Philips
Light technical	
Colour Code	922-927 [CCT of 2200K-2700K]
Luminous Flux	470 lm
Colour designation	Warm Glow (WG)

Correlated Colour Temperature	2200 2700 K
Luminous Efficacy (rated) (Nom)	138.00 lm/W
Colour consistency	<6
Colour rendering index (CRI)	90
LLMF at end of nominal lifetime (nom.)	70 %
Operating and electrical	
Line Frequency	50 to 60 Hz
Input frequency	50 to 60 Hz
Power Consumption	3.4 W
Lamp current (nom.)	24 mA
Wattage equivalent	40 W

# MASTER Value GLASS LED candles and lustres

Starting time (nom.)	0.5 s
Warm-up time to 60% light	0.5 s
Power Factor (Fraction)	0.6
Voltage (nom.)	220-240 V

## Temperature

T-Case maximum (nom.)	70 °C
-----------------------	-------

## Mechanical and housing

Lamp Finish	Clear
Bulb shape	B35 [B 35 mm]


## Approval and application

Energy consumption kWh/1,000 hours	4 kWh
	1,109,139

## Product data


Full EOC	87195143251101
Order product name	MASVLE LEDCandleDT3.4-40WE14 927B35CLGUK
Order code	32511101
SAP numerator – quantity per pack	1
Numerator – packs per outer box	10
Material number (12NC)	929003012298
Net weight	0.014 kg
Full product name	MASTERVLE LEDCandleDT3.4-40WE14 927B35CLGUK
EAN/UPC – Case	8719514405264

## Dimensional drawing

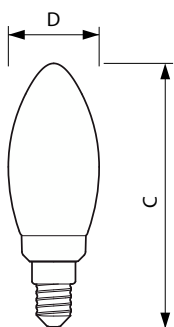


Product	D	C
MASVLE LEDCandleDT3.4-40WE14 927B35CLGUK	35 mm	97 mm

## Photometric data

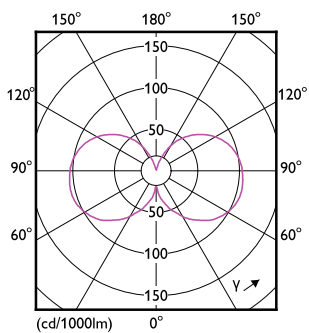


Light Distribution Diagram - MASVLE LEDCandleDT3.4-40WE14  
927B35CLGUK

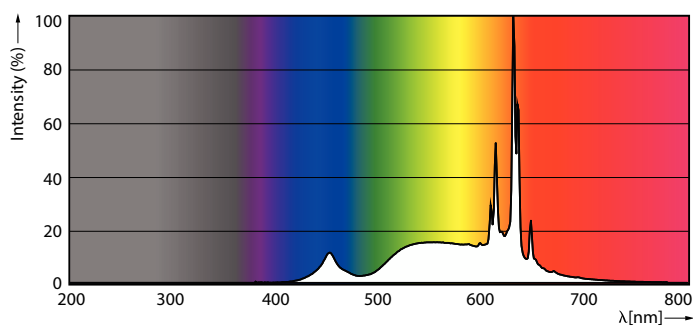



Spectral Power Distribution Colour - MASVLE LEDCandleDT3.4-40WE14  
927B35CLGUK

# MASTER Value GLASS LED candles and lustres

## Photometric data

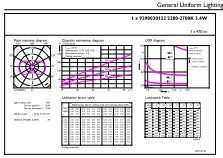

## Lifetime

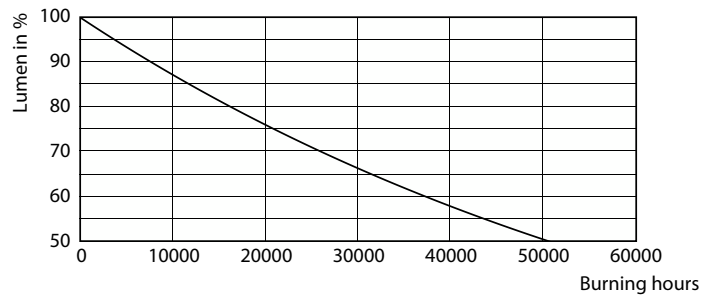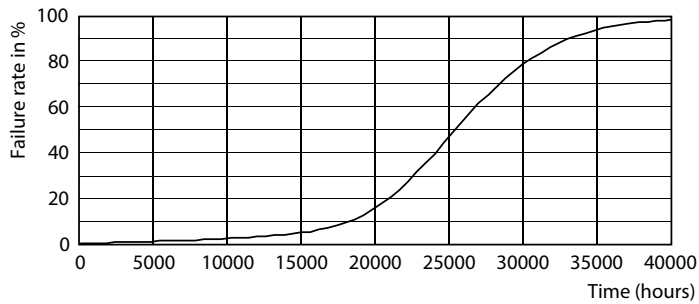

Life Expectancy Diagram - MASVLE LEDCandleDT3.4-40WE14  
927B35CLGUK

Lumen Maintenance Diagram - MASVLE LEDCandleDT3.4-40WE14  
927B35CLGUK

