

# MASTER Value GLASS LED candles and lustres

## MASTER VLE LEDCandleDT3.4-40W E14927BA35CLG

MASTER Value Glass LED lustres feature a classic heritage design, these filament LED lamps combine the familiar shapes of incandescent candles and lustres with the benefits of long-lasting LED technology. These glass LED lustres offer more energy savings than normal LED candles and lustres. At the same time, they also provide customers with a good light experience, enhanced by excellent dimming performance (dimmable LED candles). MASTER Value Glass LED lustres deliver significant energy savings, using 30% less energy compared to normal glass LED candles and provide excellent quality of light. By offering a lifetime of 15,000 hours, these dimmable LED candles and lustres also reduce maintenance costs.

### Product data

General information	
Cap base	E14 [ E14]
CE mark	Yes
EU RoHS compliant	Yes
Nominal lifetime (nom.)	15000 h
Switching cycle	20000
	Sphere
Tier	MASTER Value
Light technical	
Colour Code	922-927 [ CCT of 2,200 K-2,700 K]
Luminous flux (nom.)	470 lm

Colour designation	Warm Glow (WG)
Correlated Colour Temperature (Nom)	2200 2700 K
Luminous efficacy (rated) (nom.)	138.00 lm/W
Colour consistency	<6
Colour rendering index (nom.)	90
LLMF at end of nominal lifetime (nom.)	70 %
Operating and electrical	
Input frequency	50 to 60 Hz
Power (Rated) (Nom)	3.4 W
Lamp current (nom.)	24 mA
Wattage equivalent	40 W

# MASTER Value GLASS LED candles and lustres

Starting time (nom.)	0.5 s
Warm-up time to 60% light (nom.)	0.5 s
Power factor (nom.)	0.6
Voltage (Nom)	220-240 V

## Temperature

T-Case maximum (nom.)	70 °C
-----------------------	-------

## Controls and dimming

Dimmable	Only with specific dimmers
----------	----------------------------

## Mechanical and housing

Lamp Finish	Clear
Bulb shape	BA35

## Approval and application


Energy Efficiency Class	D
-------------------------	---

Energy consumption kWh/1,000 hours	4 kWh
	1109143

## Product data

Full product code	871951432519700
Order product name	MASTER VLE LEDCandleDT3.4-40W E14927BA35CLG
EAN/UPC – product	8719514325197
Order code	32519700
SAP numerator – quantity per pack	1
Numerator – packs per outer box	10
SAP material	929003013002
Net Weight (Piece)	0.014 kg


## Dimensional drawing

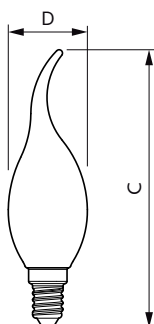


MASTER VLE LEDCandleDT3.4-40W E14927BA35CLG

Product	D	C
MASTER VLE LEDCandleDT3.4-40W E14927BA35CLG	35 mm	119 mm

## Photometric data

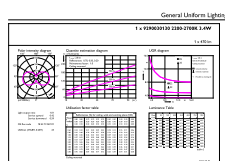


General uniform lighting

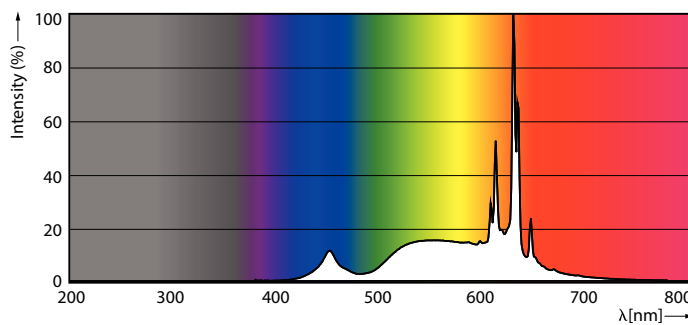

Spectral Power Distribution Colour

# MASTER Value GLASS LED candles and lustres

## Photometric data

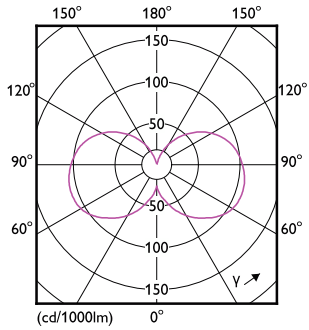

Light Distribution Diagram

## Lifetime



Life Expectancy Diagram



Lumen Maintenance Diagram

