



# MASTER GLASS LED candles and lustres



## MAS LEDCandleDT2.5-25W E14 B35 CL G

Featuring a classic heritage design, Classic filament LED Lamps combine the familiar shapes of incandescent candles and lustres with the benefits of the long-lasting LED technology. It is an idea product to provide customers with cosy atmosphere. The MASTER LED candles and lustres can be dimmed for different lumen level and also for the different colour temperature. MASTER Glass Led Bulbs deliver significant energy savings, offering even 30% more compared to normal LED. They provide excellent quality of light. By offering a lifetime of 25,000 hours, the lamps reduce maintenance costs.

### Product data

General information		Stroboscopic effect	
Lighting Technology	LED		0.4
Flux measurement reference	Sphere	Operating and electrical	
Switching Cycle	20,000	Line Frequency	50 to 60 Hz
Nominal lifetime	25,000 h	Input frequency	50 to 60 Hz
Cap base	E14 [E14]	Power Consumption	2.5 W
Light technical		Lamp current (nom.)	15 mA
Colour Code	922-927 [CCT of 2200K-2700K]	Wattage equivalent	25 W
Luminous Flux	340 lm	Starting time (nom.)	0.5 s
Colour designation	Warm Glow (WG)	Warm-up time to 60% light	0.5 s
Correlated Colour Temperature	2200 2700 K	Power Factor (Fraction)	0.6
Luminous Efficacy (rated) (Nom)	136 lm/W	Voltage (nom.)	220-240 V
Colour consistency	<6	Temperature	
Colour rendering index (CRI)	90	Ambient temperature range	-20°C to 45°C
LLMF at end of nominal lifetime (nom.)	70 %	T-Case maximum (nom.)	70 °C
Flickering value (PstLM)	0.9		

# MASTER GLASS LED candles and lustres

## Controls and dimming

Dimmable	Only with specific dimmers
----------	----------------------------

## Mechanical and housing

Lamp Finish	Clear
Bulb material	Glass
Bulb shape	B35 [B 35 mm]

## Approval and application


Energy Efficiency Class	D
Energy consumption kWh/1,000 hours	3 kWh
EPREL registration number	1109136
CE mark	Yes

EU RoHS compliant	Yes
-------------------	-----

## Product data



Full EOC	871951444935000
Order product name	MAS LEDCandleDT2.5-25W E14 B35 CL G
Order code	44935000
SAP numerator – quantity per pack	1
Numerator – packs per outer box	10
Material number (12NC)	929003011982
Full product name	MAS LEDCandleDT2.5-25W E14 B35 CL G
EAN/UPC - Case	8719514449367

## Dimensional drawing

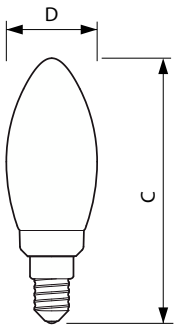

Product	D	C
MAS LEDCandleDT2.5-25W E14 B35 CL G	35 mm	97 mm

## Photometric data

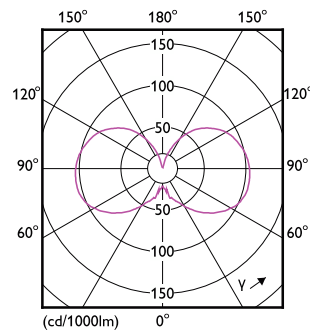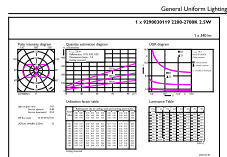


General uniform lighting - MAS LEDCandleDT2.5-25W E14 B35 CL G

Light Distribution Diagram - MAS LEDCandleDT2.5-25W E14 B35 CL G

# MASTER GLASS LED candles and lustres

## Photometric data

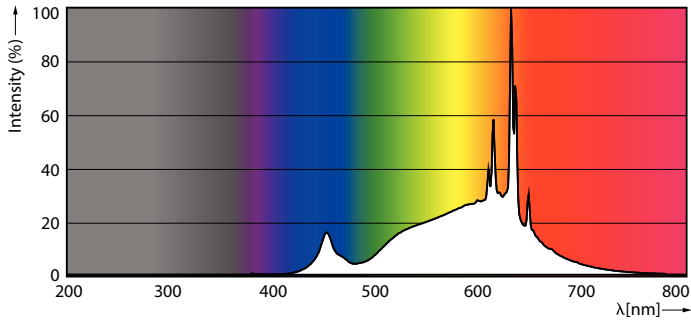

Spectral Power Distribution Colour - MAS LEDCandleDT2.5-25W E14 B35 CL G

## Lifetime



Life Expectancy Diagram - MAS LEDCandleDT2.5-25W E14 B35 CL G



Lumen Maintenance Diagram - MAS LEDCandleDT2.5-25W E14 B35 CL G

