




Replacement Tips
Item: [3C-CB-SA-RT](#)

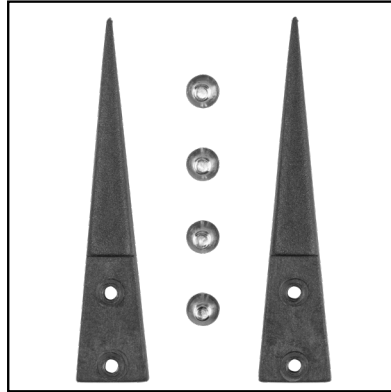

Features:

- **International Style:** 3C
- **Handle Material:** Stainless Steel
 - **Magnetic Properties:** Anti-Magnetic
 - **Corrosion Resistance:** Anti-Acid
 - **Finish:** Polished
- **Tips:** Replaceable Carbon Fiber, Short Straight, Very Fine
 - **Material:** Polyamide 66 with carbon fiber, Black
 - **Resistance:**
 - Tip to Tip: <math> < 1 \times 10^4 </math> ohms tested per ANSI/ESD STM11.12
- Made in Switzerland

Tip Specifications:

| Test | Norm | Unit | Value |
|-------------------------------|------------|-------------------|-------|
| Density | ISO 1183 | g/cm ³ | 1,28 |
| Tensile strength | ISO 527 | MPa | 210 |
| Elongation at break | ISO 527 | % | 2,5 |
| Flexural Modulus | ISO 527 | MPa | 17000 |
| Heat distribution Temperature | ASTM D 648 | °C | 95° |
| Melting point | ASTM D1525 | °C | >260° |
| Charpy impact strength | DIN 53453 | kJ/m ² | 30 |

Unless otherwise noted, tolerance is ±10%.

Specifications and procedures subject to change without notice.

PRECISION STAINLESS STEEL TWEEZER W/ REPLACEABLE CARBON FIBER TIPS, SHORT STRAIGHT TIP, VERY FINE, STYLE 3C

TRONEX

2860 CORDELIA RD STE 230, FAIRFIELD CA, 94534
PHONE: (909) 627-2453
WEBSITE: TronexTools.com

DRAWING NUMBER
3C-CB-SA-CH

DATE
June 2023