

7 Pc. Insulated Lineman's Pliers & Drivers Set


Item No.	Description	Case Pack
32858	Insulated Combo Set	3
8.0" Combination Lineman's Pliers		

Slotted: 3.5, 4.5, 5.5mm & Phillips: #0, 1, 2




Insulated Diagonal Cutters W/Stripping Holes

Item No.	Description	Case Pack
32861	6.3"/160mm	3




2 Pc. Insulated Pliers/Cutters Set

Item No.	Description	Case Pack
32862	Insulated Pliers/Cutters Set	3
8.0" BiCut SuperCut Pliers		
8.0" Combination Lineman's Pliers		




3 Pc. Insulated Pliers/Cutters Set

Item No.	Description	Case Pack
32863	Insulated Pliers/Cutters Set	1
8.0" H.Lev. Diagonal Cutters, 9.0" Lineman's Pliers, 6.3" Stripping Pliers		



3 Pc. Insulated Pliers/Cutters Set

Item No.	Description	Case Pack
32864	Insulated Pliers/Cutters Set	3
6.3" Diagonal Cutters, 8.0" Long Nose Pliers		
8.0" Combination Lineman's Pliers		



8 Pc. Insulated Pliers & SlimLine Blade Set

Item No.	Description	Case Pack
32865	Insulated Pliers/Cutters Set	1
8.0" Long Nose Pliers W/Cutters		

Insulated SlimLine Pop-Up Blade Set


Slotted: 3.0, 4.0, 5.5, 6.5 & Phillips: #1, 2



10 Pc. Insulated Pliers/Cutters & Drivers Set

Item No.	Description	Case Pack
32867	Insulated Tool Set	1
6.3" Diagonal Cutters, 9" Combo Pliers, 6.3" Long Nose Pliers, 6.3" Wire Stripper, 7" Crimping Pliers		


Slotted: 4.5, 6.0mm, Phillips: #1, 2 & Square: #2



10 Pc. Insulated Pliers/Cutters & Drivers Set

Item No.	Description	Case Pack
32868	Insulated Tool Set	1
7.0" Diagonal Cutters, 9" Combo Pliers, 8.0" Long Nose Pliers, 6.3" Wire Stripper, 7" Crimping Pliers		

Slotted: 3.0, 4.5, 6.0mm, Phillips: #1, 2




14 Pc. Insulated Pliers/Cutters & Drivers Set

Item No.	Description	Case Pack
32869	Insulated Tool Set	1
9.0" Lineman's Pliers, 8.0" High Leverage Cutters, 8.0" Cable Cutters, 8.0" Long Nose Pliers, 6.0" Stripping Pliers 10-20 AWG		

SlimeLine: Slotted: 3.0, 4.5, 6.5mm & Phillips: #1, 2

Square: #1, 2 & Terminal Driver: #2


Single Pole Tester



5 Pc. Insulated Pliers/Cutters & Drivers Set

Item No.	Description	Case Pack
32872	Insulated Belt Pack Pouch Set	3
6.3" Diagonal Cutters, 8.0" Long Nose Pliers		

Slotted: 3.0, 4.5mm & Phillips: #2



3 Pc. Insulated Pliers & Cutters Set

Item No.	Description	Case Pack
32873	Insulated Belt Pack Pouch Set	3
6.3" Diagonal Cutters, 8.0" Long Nose Pliers & 8.0" Combination Pliers		



48 Pc. Insulated Canvas Tool Bag Set

Item No.	Description	Case Pack
32874	Insulated Tool Set	1
6.3" & 8.0" Long Nose Pliers, 6.3" Combination Pliers, 9.0" Combo Pliers/Crimpers, 6.3" Side Cutters, 8.0" High Leverage Cutters, 6.3" Stripping Pliers		
8.0" Adjustable Wrench		

Slotted: 2.0 - 8.0mm, Phillips: #0 - 3, Square: #1, 2

Inch Nut Drivers: 7/32 - 1/2" & TORX: T8 - T30

T-handle Hex: 5/32 - 3/8" & Slit/Ph Terminal: #1, 2


50mm Cable Knife & 2 Meter Ruler In/mm



5 Pc. Insulated Industrial Pliers & Drivers Set

Item No.	Description	Case Pack
32875	Ins Industrial Belt Pack Pouch Set	1
9.5" Lineman's Pliers, 8.0" Long Nose Pliers		

Slotted: 4.5, 6.5mm & Phillips: #2



66 Pc. Insulated Tool Box Set

Item No.	Description	Case Pack
32876	Insulated Tool Set	1
8.0" Long Nose Pliers, 6.3" Long Flat Nose Pliers, 9.0" Combo Pliers/Crimpers, 8.0" Cable Cutters, 6.3" Side Cutters, 8.0" BiCut SuperCut, 6.3" Stripping Pliers & 8.0" Adjustable Wrench		

Slotted: 2.0-10.0mm, Phillips: #0 - 3, Square: #1, 2


Inch Nut Drivers: 1/4 - 7/16" & TORX: T8 - T30

T-handle Hex In/mm: 5/32 - 3/8" & 4.0 - 8.0mm

Slit/Ph Terminal: #1, 2 & Hex L-key: 10.0mm & 1/2"

Sockets In/mm: 1/2" - 7/8" & 8.0 - 22.0mm

4.9" Extension, 3/8" Drive Ratchet & 50mm Cable Knife



80 Pc. Insulated Master Electrician's Set

Item No.	Description	Case Pack
32877	Insulated Tool Set	1
6.3" & 8.0" Long Nose Pliers, 6.3" Bent Nose Pliers, 6.3" Long Flat Nose Pliers, 6.3" Diagonal Cutters		
9.0" Combo Pliers/Crimpers, 8.0" Cable Cutters, 8.0" BiCut SuperCut & 6.3" Stripping Pliers, 8.0" Adjustable Wrench		

Slotted: 2.0-10.0mm, Phillips: #0 - 3, Square: #1, 2

TORX: T6 - T30 & Slit/Ph Terminal: #1, 2

Nut Driver In/mm: 7/32 - 7/16" & 5.0 - 13.0mm

T-handle Hex In/mm: 5/32 - 3/8" & 4.0 - 8.0mm

Hex L-key: 10.0mm & 1/2"

Sockets In/mm: 1/2" - 7/8" & 8.0 - 22.0mm

4.9" Extension, 3/8" Drive Ratchet, 50mm Cable Stripping Knife & 2 Meter Ruler In/mm




13 Pc. Insulated Canvas Tool Bag Set

Item No.	Description	Case Pack
32878	Insulated Tool Set	1
8.0" Long Nose Pliers, 9.0" Combo Pliers/Crimpers		
8.0" High Leverage Cutters		

Slotted: 3.0, 4.5, 6.0mm & Phillips: #1, 2

Square: #1, 2 & Slit/Ph Terminal: #1, 2

50mm Cable Knife

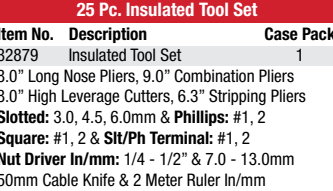

25 Pc. Insulated Tool Set

Item No.	Description	Case Pack
32879	Insulated Tool Set	1
8.0" Long Nose Pliers, 9.0" Combination Pliers		
8.0" High Leverage Cutters, 6.3" Stripping Pliers		

Slotted: 3.0, 4.5, 6.0mm & Phillips: #1, 2

Square: #1, 2 & Slit/Ph Terminal: #1, 2

Nut Driver In/mm: 1/4 - 1/2" & 7.0 - 13.0mm

50mm Cable Knife & 2 Meter Ruler In/mm



17 Pc. Pliers/Cutters & Pop Up Set

Item No.	Description	Case Pack
32886	Insulated Belt Pack Pouch Set	1
8.0" Long Nose Pliers, 8.0" High Leverage Cutters		
9.5" Lineman's Pliers		

Slotted: 4.5, 5.5, 6.0mm & Phillips: #0, 1, 2, 3


Sq: #1, 2, 3 & TORX: T15, T20, T25



11 Pc. Insulated Tool Pouch Set

Item No.	Description	Case Pack
32888	Insulated Tool Set	1
6.3" Long Nose Pliers, 8.0" Combination Pliers		
6.3" Side Cutters, 6.3" Stripping Pliers		

Slotted: 2.5, 3.5, 4.5, 6.0mm & Phillips: #0, 1, 2

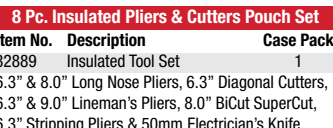

8 Pc. Insulated Pliers & Cutters Pouch Set

Item No.	Description	Case Pack
32889	Insulated Tool Set	1
6.3" & 8.0" Long Nose Pliers, 6.3" Diagonal Cutters, 6.3" & 9.0" Lineman's Pliers, 8.0" BiCut SuperCut, 6.3" Stripping Pliers & 50mm Electrician's Knife		



10 Pc. Insulated Pliers/Cutters & Drivers Set

Item No.	Description	Case Pack
32891	Insulated Tool Set	1
8.0" Long Nose Pliers, 8.0" Combination Pliers		
8.0" BiCut SuperCut, 6.3" Cable Cutters, 6.3" Stripping Pliers		

Slotted: 4.5, 6.5mm & Phillips: #1, 2, 3