


Part Number: 1860245W3DA

Type	Size	Rating	Description
LED	T10	28V AC/DC	10mm BA9s/13 LED

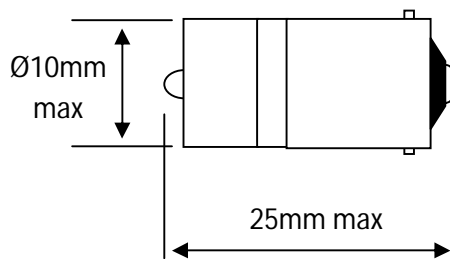

Part #	Colour	Voltage(V)	Current(mA)	Intensity(mcd)
1860245W3DA	Cool White	28VAC/DC	14	2600

Notes:

- 1 Electrical & optical data are measured at an ambient temperature of 25°C
- 2 Lamp base in accordance with BS EN 60061-1:BA9s
- 3 Storage temperature -25 °C to +80°C
- 4 Application temperature -20 °C to +60°C
- 5 Due to component tolerances, colour temperature variations may be observed
- 6 The plastic(polycarbonate) has limited chemical resistance
- 7 RoHS & REACH SVHC compliant