


Part Number: 18603X5W3A

Type	Size	Rating	Description
LED	T10	AC/DC	Miniature Edison Screw Starled

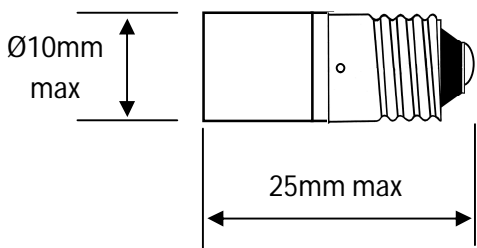

Part #	Colour	Voltage(V)	Current(mA)	Intensity(mcd)
1860325W3A	Cool White	12	15	4100
1860335W3A	Cool White	24	15	4100
1860345W3A	Cool White	28	12	3300

Notes:

- 1 Electrical & optical data are measured at an ambient temperature of 25°C
- 2 Lamp is fitted with a bridge rectifier
- 3 Lamp base in accordance with BS EN 60061-1
- 4 Storage temperature -25 °C to +80°C
- 5 Application temperature -20 °C to +60°C
- 6 Voltage tolerance ±10%
- 7 Due to component tolerances, colour temperature variations may be observed
- 8 The plastic(polycarbonate) has limited chemical resistance
- 9 RoHS & REACH SVHC compliant