


Part Number: 15701001

Type	Rating	Description
LED (5mm)	No Resistor	Status Indicator PCB mount Red/Green

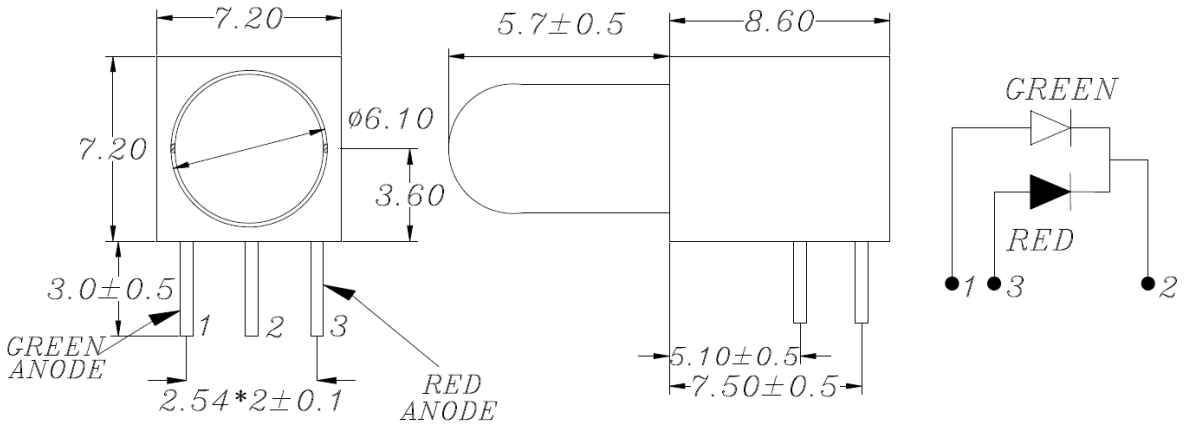

All dimension mm

Emission Colour	Lens Colour	Forward Voltage (Typ)	Current (dc)	Luminous Intensity (mcd)	Wave Length (nm)	VR Max	IR Max
Red/Green	White Diffused	2.2/2.2	20mA	200/55	625/570	5V	30mA

Notes:

1. Electrical & optical data are measured at an ambient temperature of 25°C.
2. Optical data applies to the unmounted LED.
3. Due to component tolerances, colour temperature variations may be observed.
4. RoHS & REACH SVHC compliant.
5. Operating Temperature Range -20°C to +80 °C.
6. Storage Temperature Range -30°C to +85 °C.