


Part Number: 1906XX0XWE

| Type | Size | Description |
|------|------|---|
| LED | M8 | LED Panel Mount Indicator Prominent Flashing with Leads |

Dimensions in mm (Not to scale)

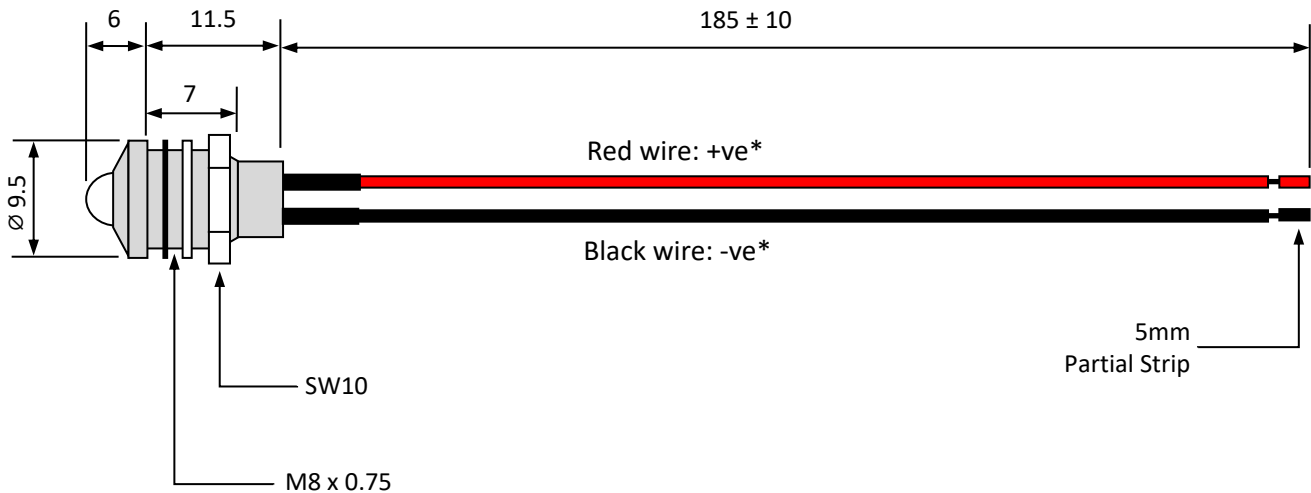

| Part Number | Colour | Rating (Vdc) | Typ Current (mA) | Typ Intensity (mcd) |
|-------------|--------|--------------|-------------------|---------------------|
| 1906x003WE | Red | 3.5 - 13 | 38 - 56 (@ 12Vdc) | 80 (@ 12Vdc) |
| 1906x303WE | Red | 24 | 38 - 56 | 80 |

x = 0: Satin chrome bezel

Notes:

- 1 Electrical & optical data are measured at an ambient temperature of 25°C
- 2 The stated luminous intensity is for dc operation
- 3 Due to component tolerances, colour temperature variations may be observed
- 4 Storage temperature range: -25 °C to +80°C
- 5 Operating temperature range: -20 °C to +60°C
- 6 The plastic (polycarbonate) has limited chemical resistance
- 7 Lead wires are externally soldered
- 8 Lead wires: 7/0.2 (24 AWG) stranded copper, tinned annealed copper wire, PVC insulation
- 9 REACH SVHC compliant
- 10 This product contains free-machining brass and is RoHS compliant via exemption clause Annex iii 6 (c) of EU Directive 2011/65/EU [Copper alloy containing lead up to 4% by weight]