


PX0841/AA/5M00 Datasheet

Product Name // Overmoulded USB 2.0 Cable PX0841
Series USB Sealed A Plug to Sealed A Plug 5m Cable

[View Product Page](#)

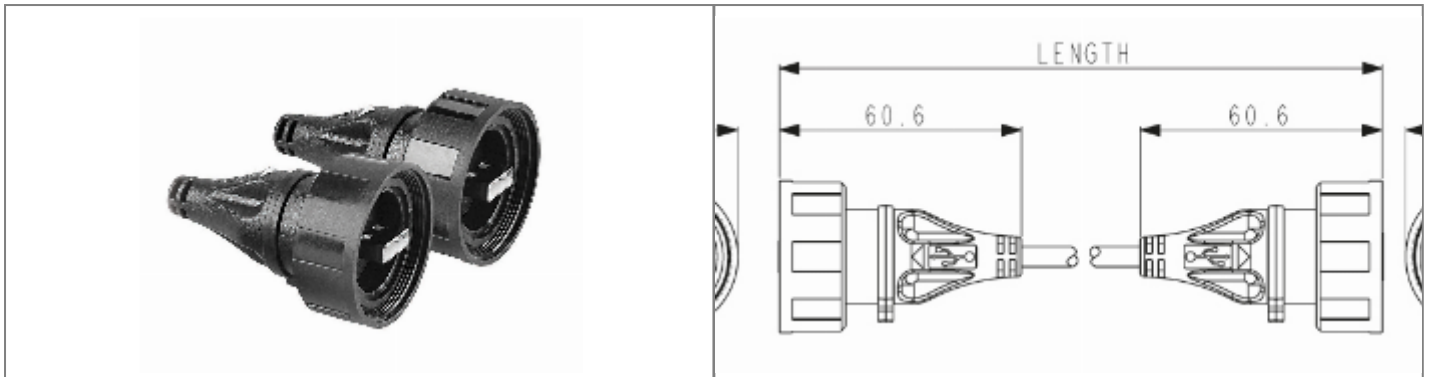

// Product Description:

- ⊞ Pre-Wired Overmoulded USB 2.0 Cable
- ⊞ Water and dustproof to IP68 when mated with compatible connector
- ⊞ Sealed Standard USB 2.0 Type A plug to Sealed Standard USB 2.0 Type A plug
- ⊞ 5m Cable Length
- ⊞ PX0835 Sealing Cap available separately to maintain IP rating of unmated connectors
- ⊞ Mate with PX08 Standard USB 2.0 Series Panel Mount Connectors

// General Information:

| | |
|---------------------------------|---|
| Product Display Title: | Pre-Wired Overmoulded USB 2.0 Cable |
| Product Family: | Circular Data Connectors |
| Product Series: | Standard Buccaneer - USB |
| Body Colour: | Black |
| Body Material: | PVC |
| Cable Length: | 5m |
| Contact Type: | Plug Contact |
| Coupling Type: | Screw |
| Current Max: | 1A |
| Data Cable Type: | USB 2.0 Sealed A Plug to Sealed A Plug |
| Diameter Over Coupling Ring Mm: | 38.1mm |
| Flamability Rating: | UL94V-0 |
| Function: | Flex to Flex Connector Double Ended Cable |
| Ip Rating: | IP68, IP69K |
| Max Operating Temperature: | +70°C |
| Min Operating Temperature: | 0°C |
| Number Of Contacts: | 4 Contacts |
| Rohs Compliant: | Yes |
| Voltage Max: | 4V |

// Product PDF Links

[Standard Series USB connectors...](#)

// Product 3D CAD Model Links

[PX0841/AA/5M003D CAD Model](#)