

Product information

49 11 A4

Precision Circlip Pliers

For external circlips on shafts

DIN 5254 A

- Heavy duty in continuous operation: up to 10 times longer service life compared to turned tips
- With inserted tips for reliable work
- Large contact faces on the tips: no distortion of circlips, easy fitting
- Bolted joint: precise, zero backlash operation of pliers
- Internal opening spring, protected and captive
- Non-slip plastic coating on the handles
- DIN 5254 A; straight jaws
- Inserted tips: spring steel wire, drawn
- Pliers body: chrome vanadium electric steel, forged, oil-hardened



MM 




General

Article No.	49 11 A4
EAN	4003773048756
Pliers	grey atramentized
Handles	with non-slip plastic coating
Weight	599 g
Dimensions	320 x 137 x 17 mm
Standard	DIN 5254 A
REACH compliant	does not contain SVHC
RoHS compliant	not applicable

Technical details

Size of shaft	Ø 85 – 140 mm
Tips (diameter)	3.2 mm

technical change and errors excepted

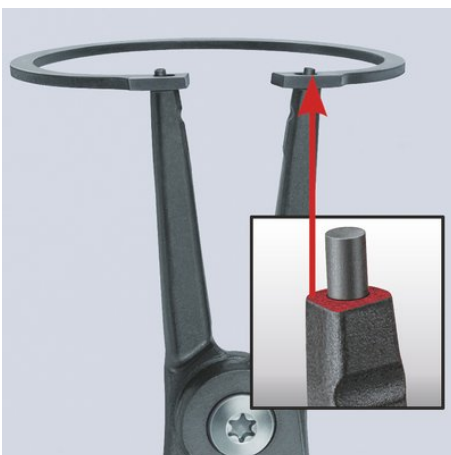

KNIPEX Precision Circlip Pliers: fit circlips without distortion; easy and quick assembling



Spring inside the joint: the spring is protected inside the precisely bolted joint. It does not hinder work and cannot get dirty or lost.