

## Product information

**22 06 160**

- For bending wire loops
- Round, short jaws; finely ground
- Smooth tips
- Special tool steel, forged, oil-hardened


### Round Nose Pliers

DIN ISO 5745 IEC 60900 DIN EN 60900



⚡ 1000V 

General	
Article No.	22 06 160
EAN	4003773033790
Pliers	chrome-plated
Head	chrome-plated
Handles	insulated with multi-component grips, VDE-tested
Weight	175 g
Dimensions	160 x 48 x 19 mm
Standard	DIN ISO 5745 DIN EN 60900 IEC 60900
REACH compliant	does not contain SVHC
RoHS compliant	not applicable
Technical details	
Jaw thickness (joint) (T1)	9.5 mm
Tips thickness (T2)	3.0 mm
Jaw length (L3)	30.0 mm
Head width (W3)	18 mm
VDE tested	yes

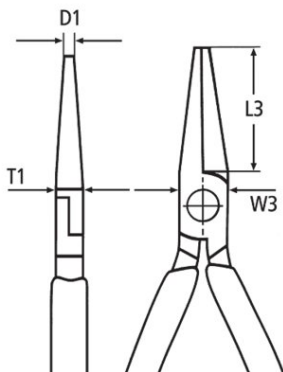

technical change and errors excepted

