




Part Number : [2145260201](#)

Product Description : Micro-Lock Plus TPA Type Receptacle Housing, 1.25mm Pitch, Low-Halogen, Single Row, Positive Lock, 2 Circuits, Black

Series Number : 214526

Status : Active

Product Category : Connector Housings

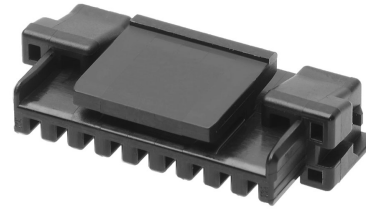

Documents & Resources

Drawings

[Drawing 2145260201_sd.pdf](#)

Specifications

[Application Specification 5055650000-AS-000.pdf](#)

[Packaging Specification 2145269200-SPK-200.pdf](#)

[Product Specification 2145260000-PS-000.pdf](#)

[Product Specification 2145260001-PS-000.pdf](#)

[Product Specification 2145260002-PS-000.pdf](#)

[Product Specification 2145260003-PS-000.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2023)3788-DC (14 Jun 2023)
EU RoHS	Compliant per EU 2015/863

[Multiple Part Product Compliance Statements](#)

- Eu RoHS
- REACH SVHC
- Low-Halogen

[Multiple Part Industry Compliance Documents](#)

- IPC 1752A Class C

- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Connector Housings
Series	214526
Description	Micro-Lock Plus TPA Type Receptacle Housing, 1.25mm Pitch, Low-Halogen, Single Row, Positive Lock, 2 Circuits, Black
Application	Wire-to-Board, Wire-to-Wire
Product Family	Micro-Lock Connector System
Product Name	Micro-Lock Plus
UPC	193264679577

Agency

UL	E29179
----	--------

Physical

Circuits (maximum)	2
Color - Resin	Black
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	PBT
Net Weight	80.660/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	1.25mm

Pitch - Termination Interface	1.25mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-40° to +105°C

Mates With / Use With

Mates with Part(s)

Description	Part Number
1.25mm Pitch Micro-Lock Plus Vertical, Single Row, Surface Mount Headers	<u>505568</u>
1.25mm Pitch Micro-Lock Plus Right-Angle, Single Row, Surface Mount Headers	<u>505567</u>
1.25mm Pitch Micro-Lock Plus Vertical, Single Row, Surface Mount Headers with Potting Capability	<u>205957</u>
1.25mm Pitch, Micro-Lock Plus Single Row Plug Housings	<u>214525</u>

Use with Part(s)

Description	Part Number
1.25mm Pitch Micro-Lock Plus TPA Retainers	<u>214528</u>
Micro-Lock Plus Female Crimp Terminals	<u>214529</u>