


External view


TAC-50-□□□ / TAC-60-□□□
TAH-50-□□□ / TAH-60-□□□

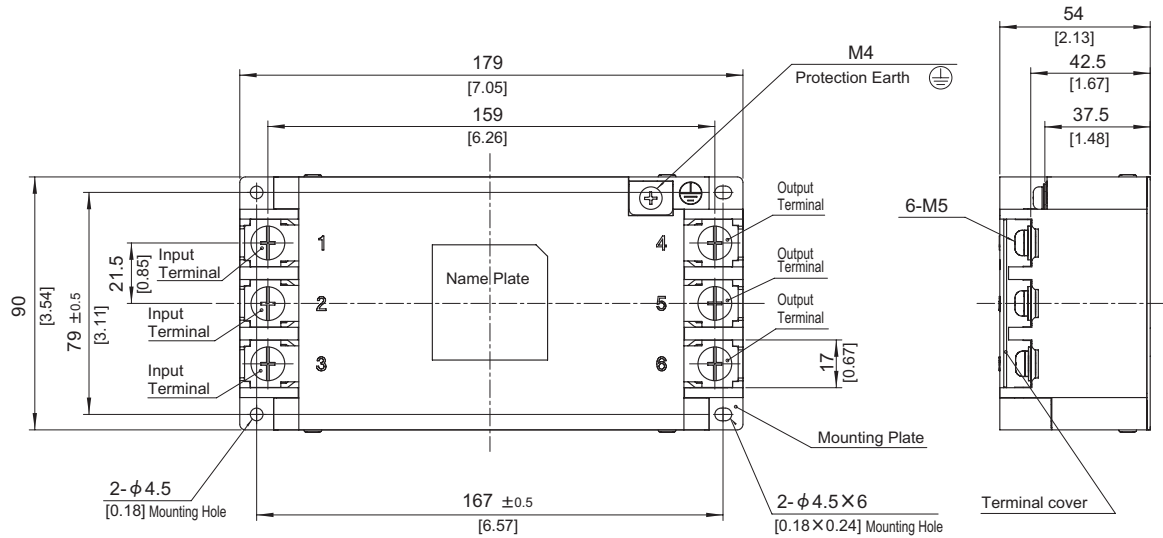

※ Can not be mounted upside-down.
(mounted the top surface)

※ Tolerance : ± 1 [±0.04]
 ※ Weight : 1.4kg max
 ※ Mounting Plate : Iron (surface finishing:nickel plating) t=1.2 [0.05]
 ※ Case : PBT
 ※ Dimensions in mm, []=inches
 ※ Terminal block screw tightening torque M5:3.0N · m (30.7kgf · cm) max
 ※ Protection Earth screw tightening torque M4:1.6N · m (16.9kgf · cm) max

TAC-80-□□□ / TAC-100-□□□
TAH-80-□□□ / TAH-100-□□□

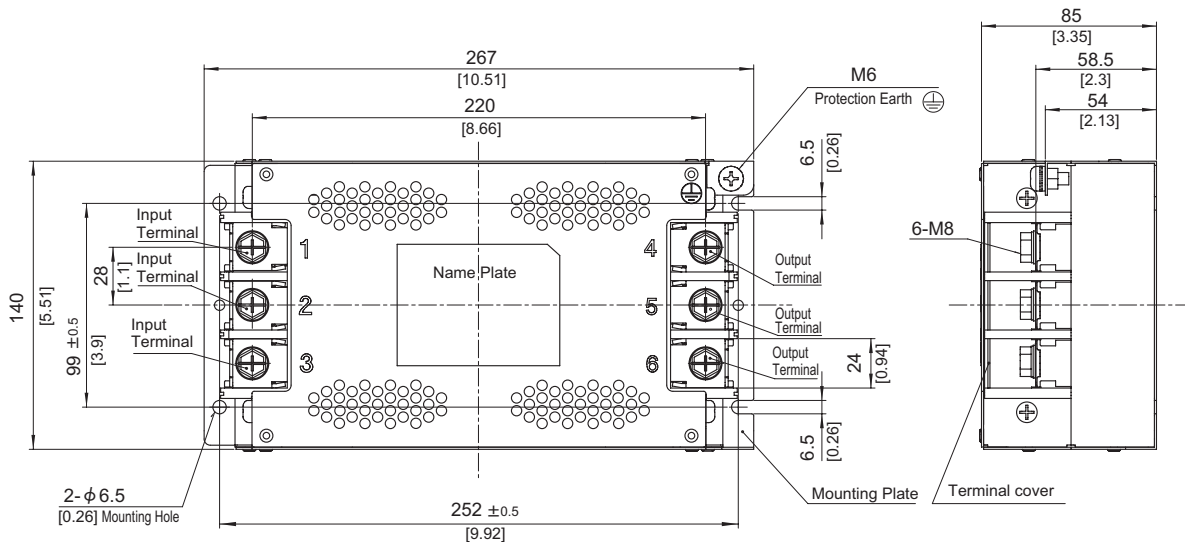


※ Can not be mounted upside-down.
(mounted the top surface)

※ Tolerance : ± 1 [±0.04]
 ※ Weight : 3.8kg max
 ※ Chassis Material : Stainless steel t=1.0 [0.04]
 ※ Dimensions in mm, []=inches
 ※ Terminal block screw tightening torque M8:9.2N · m (93.9kgf · cm) max
 ※ Protection Earth screw tightening torque M6:5.8N · m (59.2kgf · cm) max

External view

TAC-150-□□□
TAH-150-□□□

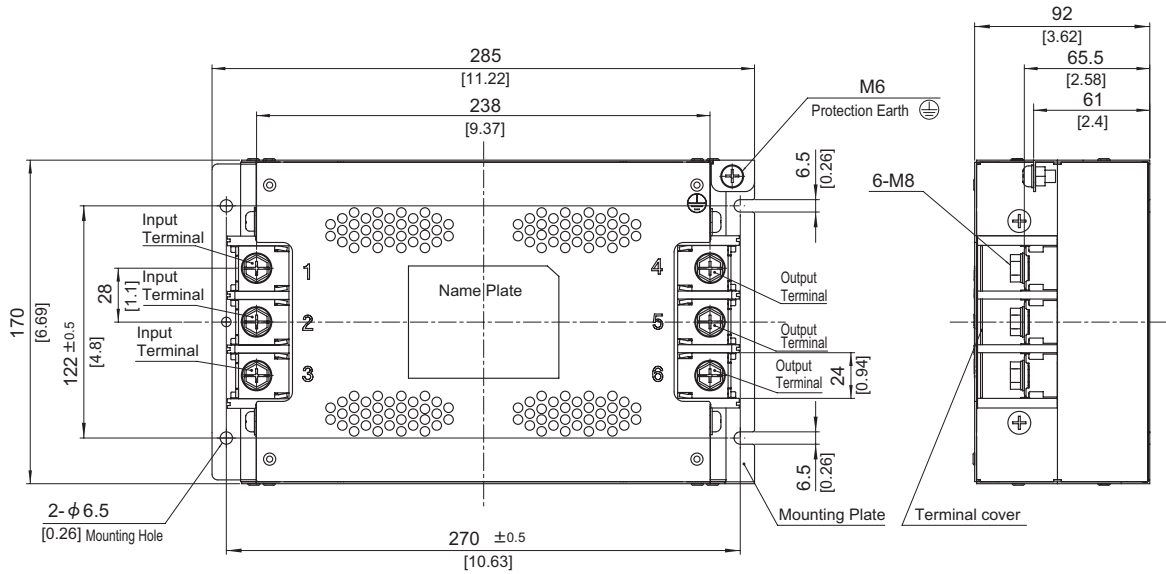

※ Can not be mounted upside-down.
(mounted the top surface)

- ※ Tolerance : ± 1 [± 0.04]
- ※ Weight : 4.8kg max
- ※ Chassis Material : Stainless steel t=1.0 [0.04]
- ※ Dimensions in mm, []=inches
- ※ Terminal block screw tightening torque M8:9.2N · m (93.9kgf · cm) max
- ※ Protection Earth screw tightening torque M6:5.8N · m (59.2kgf · cm) max