


# PXMBNI78FPM05AFL78002 Datasheet

**Product Name // 5 Contacts 7/8" Front Panel Mounting  
Male 200mm Flying Leads**

[View Product Page](#)

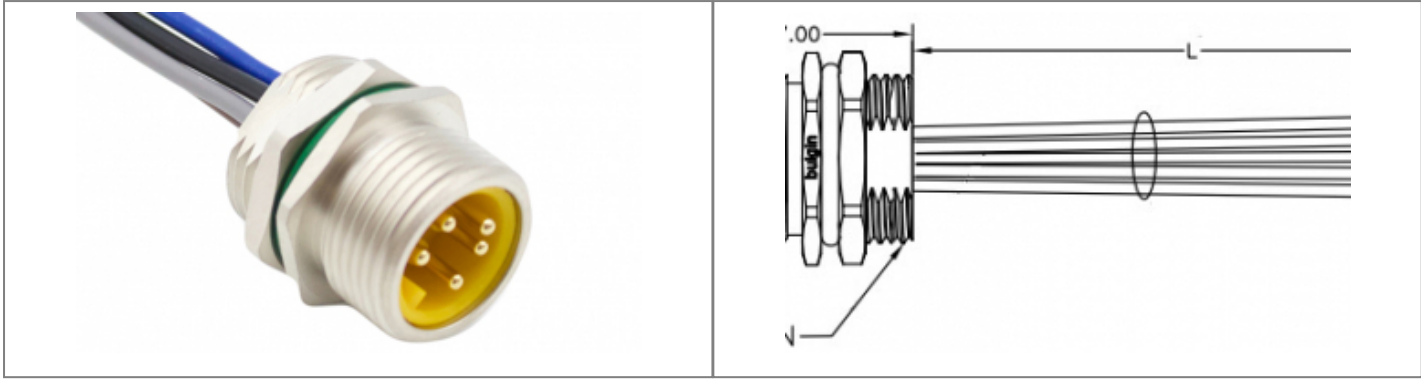

## // Product Description:

- 5 Contacts 7-8" Front Panel Mounting Male 0.2M Cable
- IP67 rated when mated
- Mechanical Cycles >100
- Operating Temperature -25°C to +85°C
- Rated Voltage 300 V
- ROHS compliance

## // General Information:

Product Display Title:	7/8" Front Panel Mounting Male 200mm Flying Leads
Product Family:	Circular Automation Connectors
Product Series:	7/8" Series
Cable Length:	0.2m
Connection Method:	Solder
Contact Type:	Plug Contact
Current Max:	9A
Durability:	>100 Cycles
Function:	Front Panel Mounting Male Connector with Flying Leads
Insulation Resistance:	>100MOhm
Ip Rating:	IP67
Max Operating Temperature:	+80°C
Min Operating Temperature:	-25°C
Number Of Contacts:	5 Contacts
Pin Layout Code:	A Code
Rohs Compliant:	Yes
Thread Size:	7/8-16UN
Voltage Max:	300V

**// Product PDF Links**

[78 Series Circular connectors...](#)