


PXMBNI78FPM03AFL78005 Datasheet

**Product Name // 3 Contacts 7/8" Front Panel Mounting
Male 500mm Flying Leads**

[View Product Page](#)

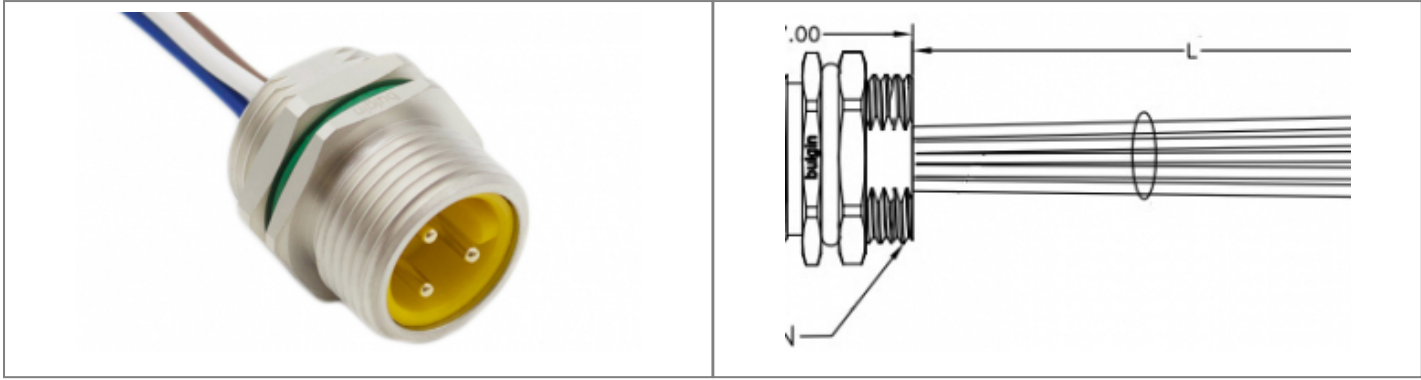

// Product Description:

- ⬢ 3 Contacts 7-8" Front Panel Mounting Male 0.5M Cable
- ⬢ IP67 rated when mated
- ⬢ Mechanical Cycles >100
- ⬢ Operating Temperature -25°C to +85°C
- ⬢ Rated Voltage 300 V
- ⬢ ROHS compliance

// General Information:

Product Display Title:	7/8" Front Panel Mounting Male 500mm Flying Leads
Product Family:	Circular Automation Connectors
Product Series:	7/8" Series
Cable Length:	0.5m
Connection Method:	Solder
Contact Type:	Plug Contact
Current Max:	12A
Durability:	>100 Cycles
Function:	Front Panel Mounting Male Connector with Flying Leads
Insulation Resistance:	>100MOhm
Ip Rating:	IP67
Max Operating Temperature:	+80°C
Min Operating Temperature:	-25°C
Number Of Contacts:	3 Contacts
Pin Layout Code:	A Code
Rohs Compliant:	Yes
Thread Size:	7/8-16UN
Voltage Max:	300V

// Product PDF Links

[78 Series Circular connectors...](#)