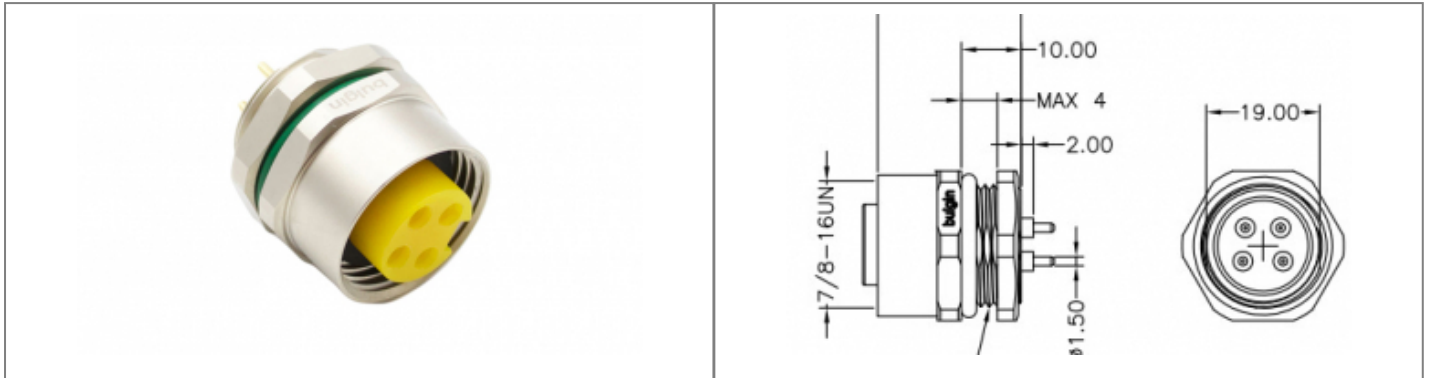


PXMBNI78FPF04APCPG135 Datasheet

Product Name // 4 Contacts 7/8" Front Panel Mounting Female Connector

[View Product Page](#)


// Product Description:

- ⊞ 3 Contacts 7-8" Front Panel Mounting Female Connector
- ⊞ IP67 rated when mated
- ⊞ Mechanical Cycles >100
- ⊞ Operating Temperature -25Å°C to +85Å°C
- ⊞ Rated Voltage 300 V
- ⊞ ROHS compliance

// General Information:

Product Display Title:	7/8" Flex Body Female Connector
Product Family:	Circular Automation Connectors
Product Series:	7/8" Series
Connection Method:	PCB
Contact Pin Material:	Phosphor bronze gold plated 1u"
Contact Type:	Socket Contact
Current Max:	9A
Durability:	>100 Cycles
Function:	Front Panel Mounting Female Connector
Insulation Resistance:	>100MOhm
Ip Rating:	IP67
Max Operating Temperature:	+85°C
Min Operating Temperature:	-25°C
Max Panel Thickness:	4.0mm
Number Of Contacts:	4 Contacts
Panel Cut Out:	20.50mmx19.20mm
Pcb Thickness:	>2.5mm
Pin Layout Code:	A Code
Rohs Compliant:	Yes
Thread Size:	PG13.5
Voltage Max:	300V

// Product PDF Links

[78 Series Circular connectors...](#)


Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)