


# PXPTPU78FBF03ACL050PUR Datasheet

**Product Name // 3 Contacts 7/8" Flex Body Female 5m Cable**

[View Product Page](#)

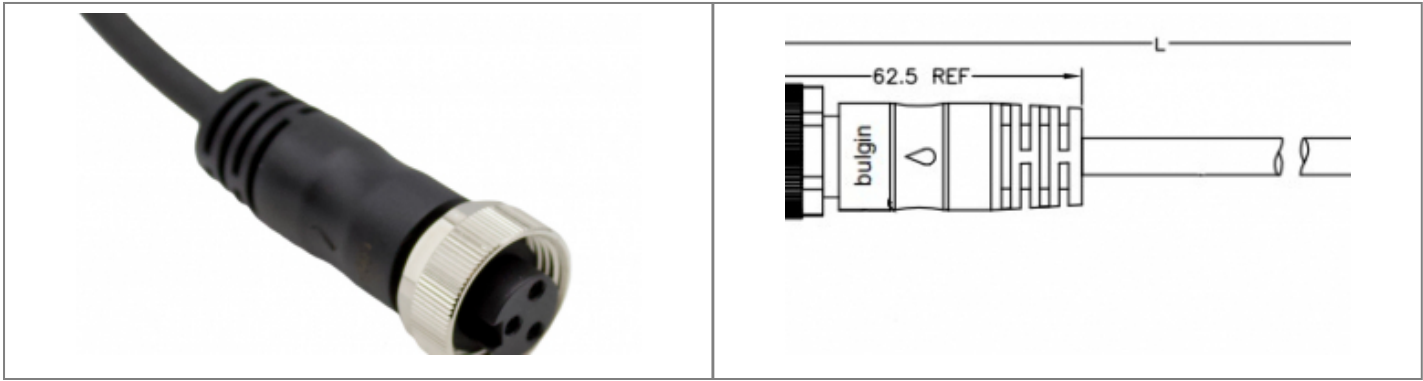

// Product Description:	
<ul style="list-style-type: none"> <li>⊕ 3 Contacts 7-8" Flex Body Female 5M Cable</li> <li>⊕ IP67 rated when mated</li> <li>⊕ Mechanical Cycles &gt;100</li> </ul>	<ul style="list-style-type: none"> <li>⊕ Operating Temperature -25Å°C to +85Å°C</li> <li>⊕ Rated Voltage 300 V</li> <li>⊕ ROHS compliance</li> </ul>

// General Information:	
Product Display Title:	7/8" Flex Body Female 5m Cable
Product Family:	Circular Automation Connectors
Product Series:	7/8" Series
Cable Length:	5m
Connection Method:	Solder
Contact Type:	Socket Contact
Current Max:	12A
Durability:	>100 Cycles
Function:	Flex Body Female Connector Single Ended Cable
Insulation Resistance:	>100MOhm
Ip Rating:	IP67
Max Cable Entry Size:	6.5mm
Max Operating Temperature:	+80°C
Min Operating Temperature:	-25°C
Number Of Contacts:	3 Contacts
Pin Layout Code:	A Code
Rohs Compliant:	Yes
Thread Size:	7/8-16UN
Voltage Max:	300V

// Product PDF Links

[78 Series Circular connectors...](#)