



**HAMMOND
MANUFACTURING®**


1427NCG Series

1427NCG Nylon Cable Glands - Metric Threads

- Liquid-tight cordgrip made from nylon
- Available in black (RAL 9005) or gray (RAL 7035).
- Used where cable is entering or leaving an enclosure.
- Accepts a wide range of cable diameters due to large opening and NBR (nitrile rubber) seal.
- The strain relief elements tighten in a circular sequence on the sealing ring to give outstanding strain relief without twisting or damaging the cable.
- Use the cordgrip with the smallest maximum diameter that will fit your application (see table below).
- Nylon locknut and EPDM o-ring included (as shown).
- Operating Temperatures:
 - Static state: -40°C to 100°C (up to 120° instantaneous)
 - Dynamic state: -20°C to 80°C (up to 100° instantaneous)
- Designed to meet NEMA Type 4, 4X, 6, 6P, 12 & 13 - Protection to IP68.
- UL94-V2 flammability rating.
- UL listed.

Part Number

1427NCGM32G

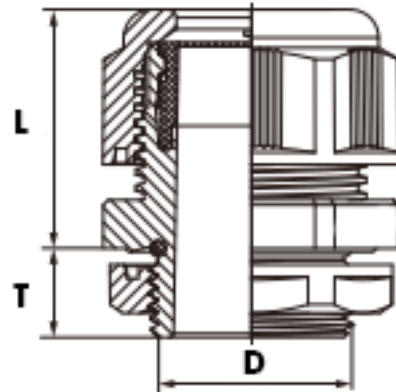

Material	Nylon
Color	Gray
Thread Size (D)	M32x1.5
Wire Diameter Min.	18 mm
Wire Diameter Max.	25 mm
Outer Length (L)	37 mm
Inner Length (T)	11mm

www.hamcfg.com/1427NCG