


# NSYSFNC108

Bottom and top frame, PanelSeT SFN, for electrical enclosure W1000 D800mm, roof included

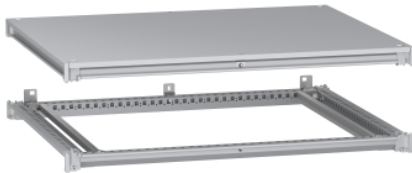

## Main

Range	PanelSeT
Accessory / separate part category	Enclosure accessory
Application	Multi-purpose
Product or component type	Framework kit
For enclosure nominal dimensions	- W: 1000 mm D: 800 mm
Mounting location	Top of vertical uprights Bottom of vertical uprights
Range compatibility	PanelSeT PanelSeT SFN
Device composition	1 bottom frame 1 roof 1 top frame
Quantity per set	Set of 1

## Complementary

Material	Steel
Colour	Grey (RAL 7035)
Surface finish	Epoxy-polyester powder
Fixing mode	By screws - each corner of enclosure location
Height	110 mm
Width	1000 mm
Depth	800 mm

## Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	101 cm
Package 1 Width	81 cm
Package 1 Length	15 cm
Package 1 Weight	24.6 kg
Unit Type of Package 2	P12
Number of Units in Package 2	8
Package 2 Height	120 cm
Package 2 Width	80 cm
Package 2 Length	125 cm
Package 2 Weight	209.8 kg

## Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)  EU RoHS Declaration
Mercury free	Yes

---

China RoHS Regulation	<a href="#">China RoHS Declaration</a>
RoHS exemption information	<a href="#">Yes</a>
Circularity Profile	No need of specific recycling operations

---

### Contractual warranty

---

Warranty	18 months
----------	-----------

---