


NSYSFNC35

Bottom and top frame, PanelSeT SFN, for electrical enclosure W300 D500mm, roof included

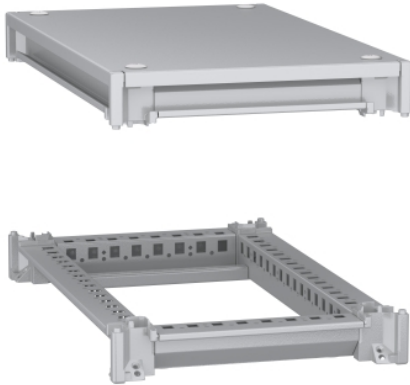

Main

Range	PanelSeT
Accessory / separate part category	Enclosure accessory
Application	Multi-purpose
Product or component type	Framework kit
For enclosure nominal dimensions	- H: 2000 mm W: 300 mm D: 500 mm
Mounting location	Bottom of vertical uprights Top of vertical uprights
Range compatibility	PanelSeT PanelSeT SFN
Device composition	1 bottom frame 1 roof 1 top frame
Quantity per set	Set of 1

Complementary

Material	Steel
Colour	Grey (RAL 7035)
Surface finish	Epoxy-polyester powder
Fixing mode	By screws - each corner of enclosure location
Height	110 mm
Width	300 mm
Depth	500 mm

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	31 cm
Package 1 Width	51 cm
Package 1 Length	15 cm
Package 1 Weight	8.8 kg
Unit Type of Package 2	PAM
Number of Units in Package 2	20
Package 2 Height	120 cm
Package 2 Width	100 cm
Package 2 Length	57 cm
Package 2 Weight	188.7 kg

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Mercury free	Yes

China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
Circularity Profile	No need of specific recycling operations

Contractual warranty

Warranty	18 months
----------	-----------
