


NSYSFNC85

Bottom and top frame, PanelSeT SFN, for electrical enclosure W800 D500mm, roof included

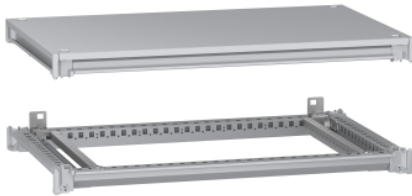

Main

| | |
|------------------------------------|---|
| Range | PanelSeT |
| Accessory / separate part category | Enclosure accessory |
| Application | Multi-purpose |
| Product or component type | Framework kit |
| For enclosure nominal dimensions | - W: 800 mm D: 500 mm |
| Mounting location | Top of vertical uprights Bottom of vertical uprights |
| Range compatibility | PanelSeT PanelSeT SFN |
| Device composition | 1 bottom frame 1 roof 1 top frame |
| Quantity per set | Set of 1 |

Complementary

| | |
|----------------|---|
| Material | Steel |
| Colour | Grey (RAL 7035) |
| Surface finish | Epoxy-polyester powder |
| Fixing mode | By screws - each corner of enclosure location |
| Height | 110 mm |
| Width | 800 mm |
| Depth | 500 mm |

Packing Units

| | |
|------------------------------|----------|
| Unit Type of Package 1 | PCE |
| Number of Units in Package 1 | 1 |
| Package 1 Height | 81 cm |
| Package 1 Width | 51 cm |
| Package 1 Length | 15 cm |
| Package 1 Weight | 15.6 kg |
| Unit Type of Package 2 | PAM |
| Number of Units in Package 2 | 16 |
| Package 2 Height | 120 cm |
| Package 2 Width | 100 cm |
| Package 2 Length | 140 cm |
| Package 2 Weight | 261.9 kg |

Offer Sustainability

| | |
|--------------------------|---|
| Sustainable offer status | Green Premium product |
| REACH Regulation | REACH Declaration |
| REACH free of SVHC | Yes |
| EU RoHS Directive | Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration |
| Mercury free | Yes |

| | |
|----------------------------|--|
| China RoHS Regulation | China RoHS Declaration |
| RoHS exemption information | Yes |
| Circularity Profile | No need of specific recycling operations |

Contractual warranty

| | |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|
