


ANSI Type U PVC Insulated Flat Pair Thermocouple Cable / Wire

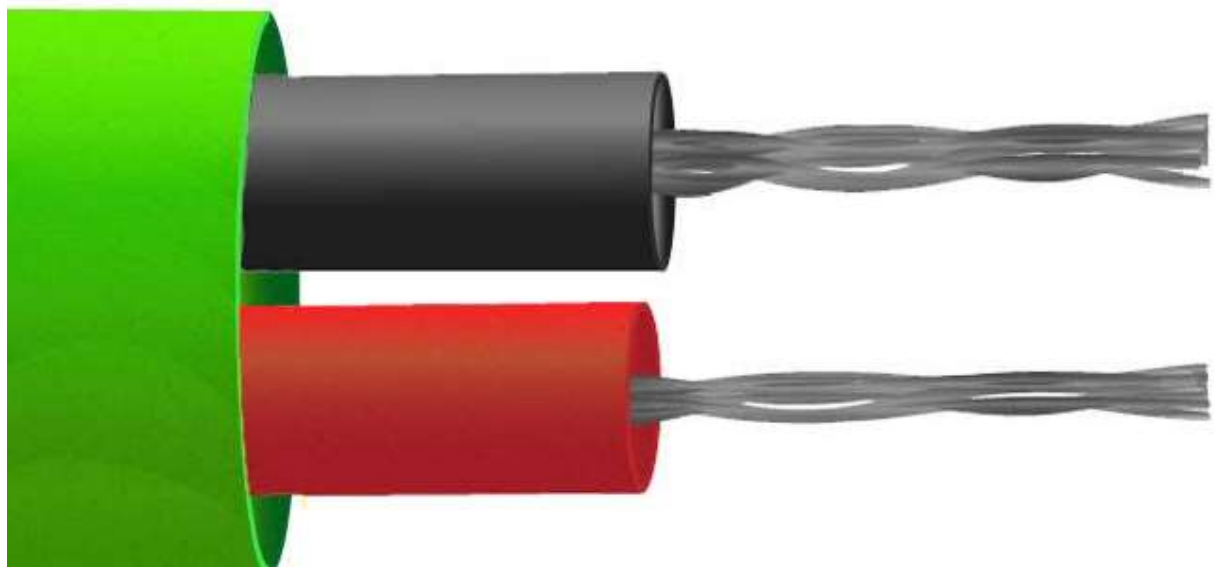

Labfacility are the UK's leading manufacturer of Temperature Sensors, Thermocouple Connectors and associated Temperature Instrumentation and stockists of Thermocouple Cables. The Company has been trading since 1971 and is ISO 9001 accredited.

Labfacility have supplied Farnell for over 30 years, and an extensive range of our products are available to buy online, from stock, direct from Farnell.

Specifications

Cable type	PVC insulated flat pair
Cable length	25 metres
Thermocouple Type	U (RSA) Cu/CuNi compensating for R & S Thermocouples
Number of cores	2
Construction	Cores laid flat with overall jacket
Conductor wire size	13/0.2mm
Conductor cross section (mm²)	0.408
Tolerance	Class 2
Loop resistance (Ohms Ω per combined metre)	0.1
Copper drain wire	No
Screen	No
Core insulation	PVC
Core insulation colour (+ Pos)	Black
Core insulation colour (-Neg)	Red
Overall jacket insulation	PVC
Overall jacket colour	Green
Overbraiding	No
Min. Temperature	-10°C
Max. Temperature	+105°C
Standards met (colour code)	ANSI MC96.1
Standards met (wire tolerance)	IEC 60584:3

Ordering Information

Type	Colour Code	Cable Style	Strand Size	Length	Manufacturers Code	Farnell Order Code
U	ANSI	PVC FLAT PAIR	13/0.2mm	25m (82ft)	WU-100-ANSI	3582385

