

iMC Laser or hand writable marking clip


Tyco iMC are marking clips designed for the identification of wires and can be permanently attached to wires, post termination.

They can be quickly and simply clipped on the wire or cable. The polyester insert strip which can be printed using a laser printer or written by hand is then inserted in the clip.

The marking clips are fastened without the need of cable ties.

Features and benefits

- Protects against damp, dust and dirt
- iMC polyester strip can be marked with a laser printer or by hand
- Quick and flexible
- iMC strip is a dual color label with white on one side and yellow on the other



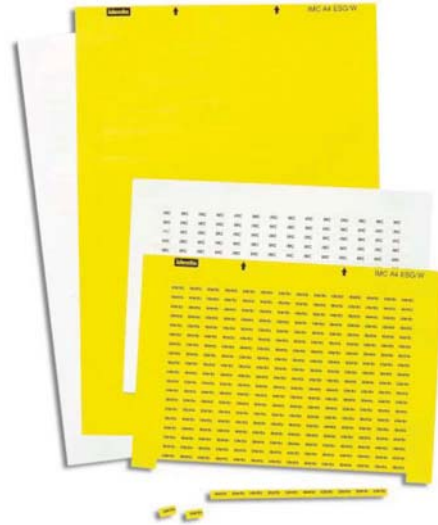
**Temperature rating**

Operating temperature +80°C (+176°F)

Printer Information

Standard laser printer with auto/manual sheet feed

Contact Tyco Electronics Electronics Identification for more information.

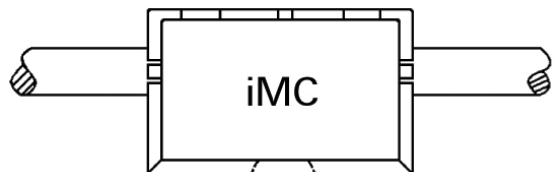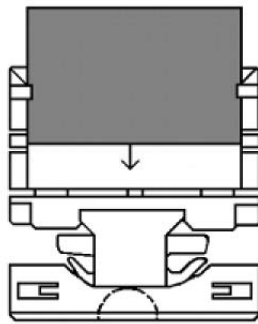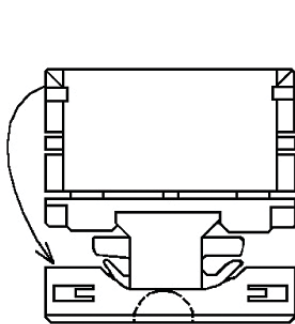

iMC Laser or hand writable marking clip (Cont'd)

Ordering Information

Marker Clips

Ordering Description	Clips per pack	Recommended Use Range mm (<i>in</i>)	Typical Cross Section mm ²	Dimensions Length x Width mm (<i>in</i>)
iMC02	500	0.75 - 2.00 <i>(0.03 - 0.08)</i>	0.20 - 0.75	15 x 7.8 <i>(0.59 - 0.31)</i>
iMC04	500	1.75 - 3.25 <i>(0.07 - 0.13)</i>	0.50 - 1.50	15 x 7.8 <i>(0.59 - 0.31)</i>
iMC06	500	3.00 - 4.50 <i>(0.12 - 0.18)</i>	1.50 - 6.00	15 x 9.5 <i>(0.59 - 0.37)</i>
iMC08	500	4.25 - 6.00 <i>(0.17 - 0.24)</i>	6.00 - 10.00	15 x 9.5 <i>(0.59 - 0.37)</i>

Legend Strips (A4 Sheets)

Ordering Description	Labels per sheet	Color	Label Size Height x Width mm (<i>in</i>)
iMCA4ES-4/9	560	1 side White 1 side Yellow	6.4 x 12.2 <i>(0.25 x 0.48)</i>