

601966-1 ✓ ACTIVE

AMP

TE Internal #: 601966-1

Hand Crimping Tools, Premium Crimp Tooling, Not Releasable,
Not Adjustable, Fixed In Tool, MIL Spec, Pneumatic / Manual, Four
Indent Hand Tool

[View on TE.com >](#)



Application Tooling > Hand Crimping Tools



Tool Grade: **Premium Crimp Tooling**

Ratchet Configuration: **Not Releasable, Not Adjustable**

Die Sets Type: **Fixed In Tool**

Specification Type: **MIL Spec**

TE Certification: **Upon Request for Fee**

Features

Other

Crimp Form-Wire Barrel Type	Closed Barrel - 4 Indent
Tool Grade	Premium Crimp Tooling
Ratchet Configuration	Not Releasable, Not Adjustable
Die Sets Type	Fixed In Tool
Specification Type	MIL Spec
TE Certification	Upon Request for Fee
Power Technology Type	Manual, Pneumatic
Tooling Type	Four Indent Hand Tool

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Out of Scope
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2023 (235) Candidate List Declared Against: JUL 2021 (219) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per

homogenous material. Also BFR/CFR/PVC Free

Solder Process Capability

Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # CAT-M1-ST814
M12 Straight Crimped Strain Relief



TE Part # CAT-AM71-C83998M
CPC Connectors, Series 2




TE Part # CAT-M1-P489D
M12 Crimp Contact for A8 Code



TE Part # CAT-AM71-C83998BB
CPC SERIES 3



TE Part # CAT-M1-R4491
M12 Right Angle Crimped Strain Relief



TE Part # CAT-M1-P489
M12 Straight D4 PG Clamp



TE Part # CAT-M1-P489C
M12 Crimp Contact For D and A5



TE Part # CAT-M1-ST814D
M12 Panel Mount Crimped Strain Relief



TE Part # 205564-2
AMPLIMITE,ASY,PLUG,STD,109,5




TE Part # 205563-2
RECEPT ASSY,50 POSN,AMPLIMITE



TE Part # 205562-2
AMPLIMITE,ASY,PLUG,STD,109,4



TE Part # 205560-2
AMPLIMITE,ASY,PLUG,STD,109,3

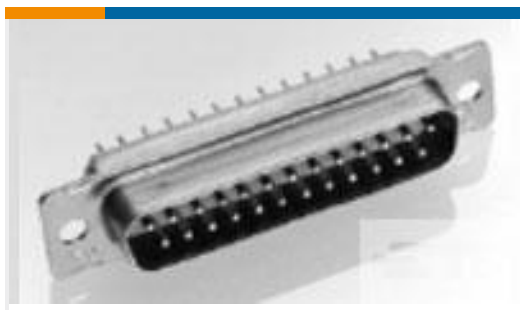

TE Part # 205561-2
RECEPT ASSY,37 POSN,AMPLIMITE



TE Part # 1757823-5
AMPLIMITE,ASY,PLUG,STD,90,ZN,5



TE Part # 1757820-7
AMPLIMITE,ASY,RCPT,STD,109,ZN,2,CT



TE Part # 1757819-7
AMPLIMITE,ASY,PLUG,STD,109,ZN,2,CT




TE Part # 1757819-5
AMPLIMITE,ASY,PLUG,STD,109,ZN,5



TE Part # 205559-2
RECEPT ASSY,25 POSN,AMPLIMITE



TE Part # 1757819-9
AMPLIMITE,ASY,PLUG,STD,109,ZN,4,CT

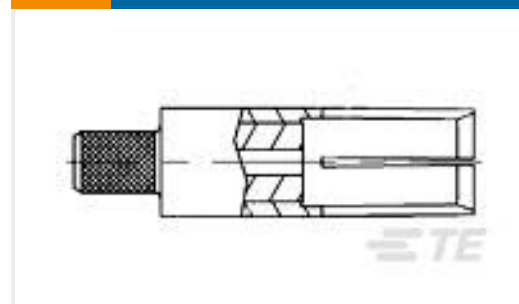


TE Part # 225791-2
COAXIAL RF SOCKET, SZ 5


Customers Also Bought



TE Part #169311-000
55A1822-24-9/96-9CS2275

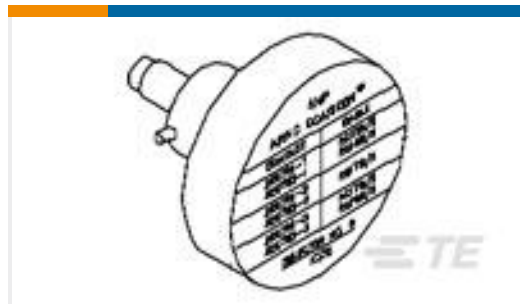

TE Part #1-601966-4
POSITIONIER FOR 601966-1

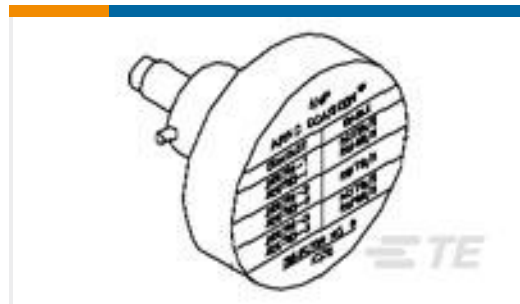

TE Part #1-601966-3
POSITIONIER




TE Part #601966-2
POSITIONIER-M22520/2-02



TE Part #91067-2
INSERTION/EXTRACTION TOOL



TE Part #91067-1
INSERTION/EXTRACTION TOOL

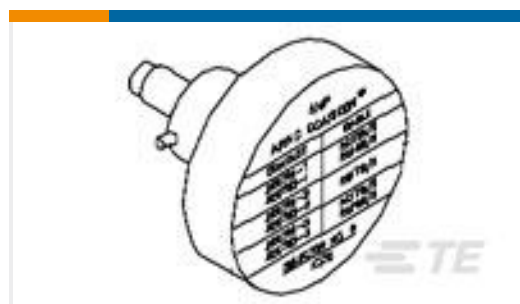


TE Part #601966-4
K-41 POSITIONIER



TE Part #601966-6
NO PRINT *A.S.I.*



TE Part #601963-3
POSITIONIER M22520/4-02

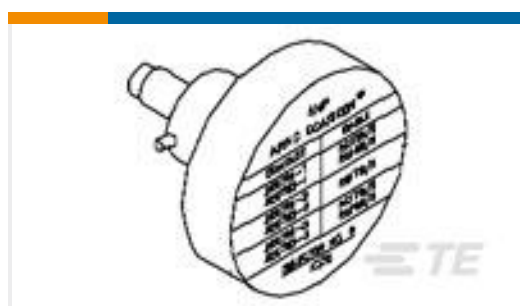

TE Part #601966-8
POSITIONIER, K267-1

Documents



Datasheets & Catalog Pages

[AMP Circular Connectors for Commercial Signal & Power Applications](#)

English

Instruction Sheets

[Instruction Sheet \(U.S.\)](#)

English

Agency Approvals

[CSA Certificate](#)

English