


**TDK item description** 60722YP251K4DAS


**Applications** For Distribution Lines

**Feature** SF6 Gas Insulated SF6 Gas (Insulation Type)

**Series** FD

**Status**  Production

**Brand** TDK

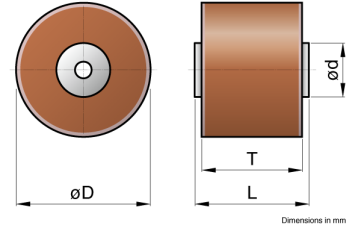

Size	
D	30.00mm ±1.00mm
L	33.20mm ±1.00mm
T	29.20mm ±2.00mm
d	10.00mm ±0.50mm
Screw Thread	ISO M4

Electrical Characteristics	
Capacitance	250pF ±10%
Rated Voltage	20kVAC
Withstanding Voltage (Nom.)	30kVAC
AC Corona Starting Voltage [3pC] (Min.)	24kVAC
Lightning Impulse Withstand Voltage (Min.)	
Temperature Characteristic	Y5P(±10%)
Dissipation Factor (Max.)	0.3%
Insulation Resistance (Min.)	10000MΩ

Other	
Operating Temperature Range	-30 to 85°C
Storage Temperature Range	-30 to 85°C
Packing	Box

! Images are for reference only and show exemplary products.  
! This PDF document was created based on the data listed on the TDK Corporation website.  
! All specifications are subject to change without notice.